

JB and GS Flexible Fixture Hangers

Malleable Iron. Ball Type, 15° Swing; Cushion Type, 8° Swing

UNILETS® for Use with Threaded Rigid Metal Conduit and IMC.

NEC/CEC:

Listed for Ordinary (Unclassified) Locations

Applications

- JB, GS and AHG cushion hangers are enclosed and gasketed—ideal where dust and dampness are present.
- JB and GS hangers designed for use with JB and GS boxes.

Features

- All hangers
 - All fixture hangers protect fixture against wind and vibration damage.
 - Cushion type for added protection where lighting fixtures are subjected to vibration.
- JB and GS hangers
 - Mount directly to JB and GS cast conduit outlet boxes.
 - Choice of ball or cushion type.
 - Ball type permits 15° swing, cushion type 8° swing from vertical
 - Cushion type is enclosed and gasketed.

Standard Materials

- Malleable iron


Standard Finishes

- GS: triple-coat—(1) zinc electroplate, (2) chromate, and (3) epoxy powder coat
- JB series support: zinc electroplate and clear chromate

NEC/CEC Certifications and Compliances

- JB and GS cushion type hangers suitable for classified location use in Class I, Division 2 areas, if installed in compliance with NEC 501-9(b)
- CSA Certified: 065180
- UL Listed: E109438

Illustrated Features

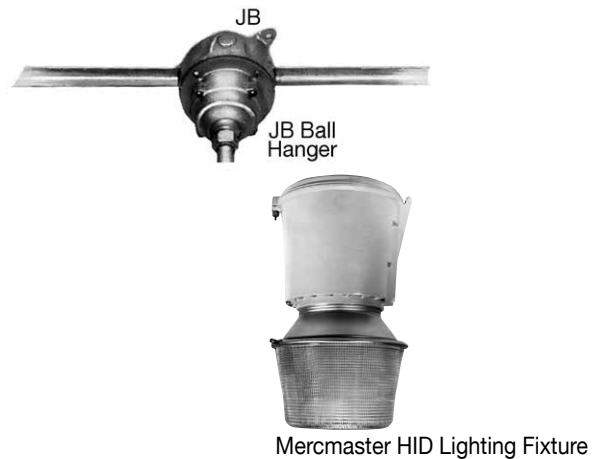


JBK-50-BS



JBK-50-CS



GSK-50-20B

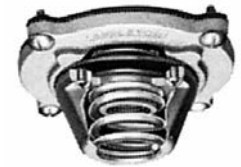

GSK-50-20C

POLES/HANGERS: NEC/CEC ORDINARY LOCATION FLEXIBLE FIXTURE HANGERS

Appleton®

JB and GS Flexible Fixture Hangers





Malleable Iron. Ball Type, 15° Swing; Cushion Type, 8° Swing

UNILETS® for Use with Threaded Rigid Metal Conduit and IMC.

NEC/CEC:

Listed for Ordinary (Unclassified) Locations

POLES/HANGERS: NEC/CEC ORDINARY LOCATION FLEXIBLE FIXTURE HANGERS

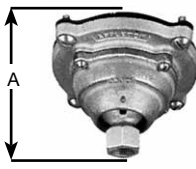	Fixture Stem Size (Inches)	Male Nipple Size (Inches)	Length A mm (in)	Support Weight kg (lbs)	Catalog Number
JB—Fixture Hanger Covers — For use with JBX, JBDX and JBLX bodies — Furnished with gasket and screws					
	Ball Type				
	1/2		65.0 (2.56)	113 (250)	JBK-50-BS
3/4		65.0 (2.56)	JBK-75-BS		
	Cushion Type				
	Enclosed and gasketed. Cushions 18.0 kg. (40 lbs.)				
	1/2		41.4 (1.63)	18 (40)	JBK-50-CS
	3/4		41.4 (1.63)		JBK-75-CS
GS—Fixture Hanger Covers (Form 20) — For use with GS and GSU bodies — Furnished with gasket and screws					
	Ball Type				
	1/2		76.2 (3.00)	250 (113)	GSK-50-20B
3/4		82.6 (3.25)	GSK-75-20B		
	Cushion Type				
	Enclosed and gasketed. Cushions 18.0 kg. (40 lbs.)				
	1/2		50.8 (2.00)	40 (18)	GSK-50-20C
	3/4		50.8 (2.00)		GSK-75-20C