

# APPLETON™ LIGHTING POLES, MOUNTING BRACKETS AND ACCESSORIES

## Applications

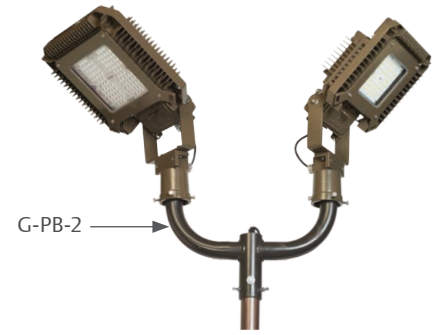
- These lighting poles, mounting brackets, and accessories are used to mount single or multiple luminaires at heights ranging from 14 feet to 39 feet.
- Lighting pole types include hinged steel poles, square steel poles, square tapered steel poles, and round tapered steel poles.

## Streamlined Ordering Process

- All lighting poles have been standardized, and pricing can be found on Members Only. For a lighting pole catalog item to be added to an SPA, please contact Pricing.AppletonGroup@Emerson.com.
- Discount code: **APPLBK**

 

 



## Stocking Program

- Multiple lighting brackets and accessories are stocked items, and have an average lead time of two days.
- Stocked brackets: G-PB-2, G-PB-2-GAL, G-PB-3-GAL, G-PB-4-GAL, G-PWB-1, G-PSWB6-GAL



*Areamaster™ Generation 2 LED with G-PB-2 Mounting Bracket*

## Standard Lighting Pole Features and Components — All Hardware for Pole Assembly is Provided







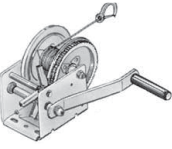
 

	Features	Description
	Tenon pole top	All poles come standard with a 2-3/8" pipe size tenon top, which accepts a single luminaire; or two, three, or four luminaires with appropriate pole-top mounting bracket.
	Handhole and cover	A 3"x5" reinforced handhole with cover and grounding lug above pole base is standard on all poles. Handhole covers are supplied with a waterproofing gasket.
	Base plate cover	A full base plate cover, made of automotive structural grade steel, comes standard with all poles. The base plate cover is rust proof and tamper resistant.
	Anchor bolts	Anchor bolts are furnished complete with nuts and washers, conform to ASTM F1554 Gr. 55, and are galvanized. All anchor bolts will be pre-shipped ahead of lighting pole(s).
	Finish	All poles come standard with a dark bronze powder coat finish, (as is used on the pictured AMLED67) unless the "-GAL" suffix is used to indicate a galvanized finish.
	Base plate	Base plate sizes range from 8" to 13" square, made of structural quality steel with a minimum yield strength of 86,000 psi. All base plate templates (and anchor bolts) will be pre-shipped ahead of the lighting pole(s).

APPLETON™



EMERSON. CONSIDER IT SOLVED.™

Standard — Lighting Pole Accessories

	Description	Finish	Catalog Number
	Pole-top bracket for two luminaires	Bronze	G-PB-2 ①
		Galvanized	G-PB-2-GAL ①
	Pole-top bracket for three luminaires	Bronze	G-PB-3
		Galvanized	G-PB-3-GAL ①
	Pole-top bracket for three luminaires (120° apart)	Bronze	G-PB-3-120
		Galvanized	G-PB-3-120-GAL
	Pole-top bracket for four luminaires (in line)	Bronze	G-PB-14
		Galvanized	G-PB-14-GAL
	Pole-top bracket for four luminaires	Bronze	G-PB-4
		Galvanized	G-PB-4-GAL ①
	Pole-top reducer (2-1/2" to 2")	Bronze	GPR212
	Pole-top reducer (3" to 2")	Bronze	GPR3
	Pole-top reducer (3-1/2" to 2")	Bronze	GPR312
	Pole-top reducer (4" to 2")	Bronze	GPR4
	Pole-top reducer (5" to 2")	Bronze	GPR5
	Lowering winch for 20 foot hinged pole	—	GLW20
	Lowering winch for 24 foot hinged pole	—	GLW24
	Lowering winch for 30 foot hinged pole	—	GLW30
	Lowering winch for 35 foot hinged pole	—	GLW35
	Wall mounting bracket for floodlights with 50.8 mm (2 in) slip-fitter, or will mount G-PB Series brackets with floodlights	Bronze	G-PWB-1 ①
	Wall mounting bracket used with G-AM-8-SF and GSF-20 to provide a wall mounting option	Galvanized	G-PSWB-6-GAL ①

① Bracket is stocked, with a two-day lead time.

Standard, Made to Order — Lighting Poles

Description	Mounting Height in Feet	Catalog Number	
		Bronze	Galvanized
Round Tapered Steel Poles	20	G-PRTH-20	G-PRTH-20-GAL
Round Tapered Steel Poles	25	G-PRTH-25	G-PRTH-25-GAL
Round Tapered Steel Poles	30	G-PRTH-30	G-PRTH-30-GAL
Round Tapered Steel Poles	35	G-PRTH-35	G-PRTH-35-GAL
Round Tapered Steel Poles	39	G-PRTH-39	G-PRTH-39-GAL
Hinged Steel Poles	20	G-PHSH-20	G-PHSH-20-GAL
Hinged Steel Poles	24	G-PHSH-24	G-PHSH-24-GAL
Hinged Steel Poles	30	G-PHSH-30	G-PHSH-30-GAL
Hinged Steel Poles	35	G-PHSH-35	G-PHSH-35-GAL
Square Tapered Steel Poles	20	G-PSTH-20	G-PSTH-20-GAL
Square Tapered Steel Poles	25	G-PSTH-25	G-PSTH-25-GAL
Square Tapered Steel Poles	30	G-PSTH-30	G-PSTH-30-GAL
Square Tapered Steel Poles	35	G-PSTH-35	G-PSTH-35-GAL
Square Tapered Steel Poles	39	G-PSTH-39	G-PSTH-39-GAL
Square Steel Poles	14	G-PSSH-14	G-PSSH-14-GAL
Square Steel Poles	17	G-PSSH-17	G-PSSH-17-GAL
Square Steel Poles	20	G-PSSH-20	G-PSSH-20-GAL
Square Steel Poles	25	G-PSSH-25	G-PSSH-25-GAL
Square Steel Poles	30	G-PSSH-30	G-PSSH-30-GAL