

## Industrial Specification Grade Straight Blade Plugs & Connectors


2-Pole, 3-Wire Grounding  
15A, 125V/AC  
NEMA 5-15



5-15P




5-15R

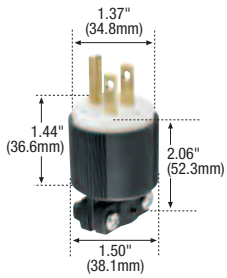

6266




5269N

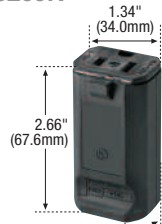

5266N



5969BLK

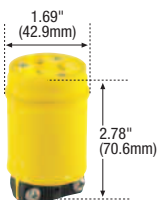

14W47

Industrial Grade Dimensional  
Information: B-18

Specification Information:

Safety Grip Industrial Plugs &  
Connectors: B-26

AutoGrip Industrial Plugs &  
Connectors: B-26

Corrosion Resistant AutoGrip  
Industrial Plugs &  
Connectors: B-29

QuickGrip Plugs &  
Connectors: B-26

Watertight Industrial Plugs &  
Connectors: B-28

Severe Duty Industrial  
Plugs & Connectors: B-29

## Industrial Grade Plugs & Connectors

### Safety Grip™ NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.33-0.66" (6.4-16.7mm)	Black & White	<input type="checkbox"/> 6266	<input checked="" type="checkbox"/> 6269	<input type="checkbox"/> 6269
			Straight Body 0.33-0.66" (6.4-16.7mm)	Black	<input type="checkbox"/> 6266BLK	<input checked="" type="checkbox"/> 6269BLK	<input type="checkbox"/> 6269BLK
			Angled Body 0.33-0.66" (7.6-16.7mm)	Black & White	<input type="checkbox"/> 6265	<input checked="" type="checkbox"/>	<input type="checkbox"/>

### AutoGrip™ NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.33-0.66" (6.4-16.7mm)	Black & White	<input type="checkbox"/> 5266N	<input checked="" type="checkbox"/> 5269N	<input type="checkbox"/> 5269N
			Corrosion Resistant, Straight Body 0.33-0.66" (6.4-16.7mm)	Yellow	<input type="checkbox"/> 5266NCR	<input checked="" type="checkbox"/> 5269NCR	<input type="checkbox"/> 5269NCR

### QuickGrip™ NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.23-0.72" (5.8-18.3mm)	Black	<input type="checkbox"/> 5965BLK	<input checked="" type="checkbox"/> 5969BLK	<input type="checkbox"/> 5969BLK

### Watertight NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.30-0.65" (7.6-16.5mm)	Yellow	<input type="checkbox"/> 14W47	<input checked="" type="checkbox"/> 15W47	<input type="checkbox"/> 15W47
			Straight Body 0.30-0.65" (7.6-16.5mm)	Black	<input type="checkbox"/> 14W47BK	<input checked="" type="checkbox"/> 15W47BK	<input type="checkbox"/> 15W47BK

### Severe Duty NEMA 5-15



Rating	A	V/AC	Product Type & Cord Diameter	Color	Plug	Catalog No.	Connector
15	125		Straight Body 0.38-1.00" (19.1-25.4mm)	Yellow & Black	<input type="checkbox"/> 1447	<input checked="" type="checkbox"/> 1547	<input type="checkbox"/> 1547

### Icon Key

NAFTA Compliant - see page O-30

## Accessories for Industrial Grade NEMA 5-15 Plugs & Connectors

Description	Catalog No.
Watertight plug closure cap for 15A plug	<input type="checkbox"/> 14W
Replacement watertight connector closure cap for 15A connector	<input type="checkbox"/> 15W
Wire mesh grip for 15A watertight plugs & connectors, 0.30-0.50" (7.6-12.7mm) cord dia.	<input type="checkbox"/> WM115
Wire mesh grip for 15A watertight plugs & connectors, 0.50-0.62" (12.7-15.8mm) cord dia.	<input type="checkbox"/> WM116



14W



15W



WM115



WM116