



### Hart lock industrial grade 20A locking devices

#### Product description


3-pole, 3-wire non-grounding  
20A, 3Ø 480V/AC  
NEMA L12-20

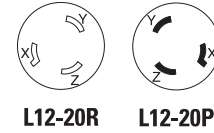

CWL1220P

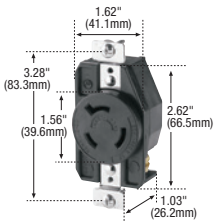

CWL1220R

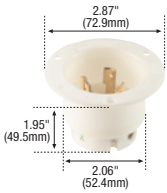

CWL1220FI

#### Industrial grade plugs & connectors

Rating		NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
A	V/AC							
20	480	L12-20	3Ø straight body	0.38-1.00" (9.5-25.4mm)	BK & W	<input type="checkbox"/> CWL1220P	<input type="checkbox"/> CWL1220C	

#### Industrial grade receptacles

Rating		NEMA	Description	Color	Single receptacle	
A	V/AC					
20	480	L12-20	3Ø standard industrial	BK	<input type="checkbox"/> CWL1220R	

#### Industrial grade inlets & outlets

Rating		NEMA	Description	Color	Flanged inlet	Flanged outlet	
A	V/AC						
20	480	L12-20	3Ø standard industrial	W	<input type="checkbox"/> CWL1220FI	—	
			3Ø standard industrial	W	—	<input type="checkbox"/> CWL1220FO <sup>†</sup>	

<sup>†</sup>Only UL and CSA Listed

#### Accessories for NEMA L12-20 locking devices

Description	Catalog no.		
Diecast aluminum single receptacle cover, vertical mount, for FS/FD boxes	<input type="checkbox"/> 7420		
Glass-filled nylon flanged inlet/outlet cover, vertical mount, for 20A devices	<input type="checkbox"/> WP2		



7420



WP2

#### Color information:

BK (Black), W (White)



**Dimensional information:**  
C-77, C-78

**Receptacle specification information:**  
K12-20: C-87

**Compliances, specifications and availability are subject to change without notice.**