
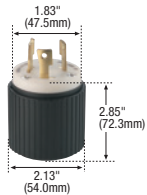



Hart lock industrial grade 30A locking devices

Product description

3-pole, 3-wire non-grounding
30A, 3Ø 480V/AC
NEMA L12-30

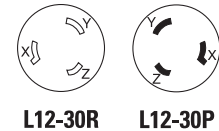


CWL1230P

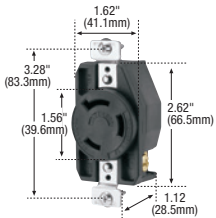

CWL1230R



CWL1230FO

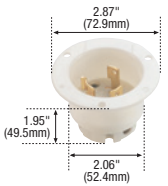

CWL1230FI

Industrial grade plugs & connectors



Rating	A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
30	480	L12-30	3Ø straight body	0.38-1.00" (9.5-25.4mm)	BK & W	<input type="checkbox"/> CWL1230P	<input type="checkbox"/> CWL1230C		•

Industrial grade receptacles



Rating	A	V/AC	NEMA	Description	Color	Single receptacle	
30	480	L12-30	3Ø standard industrial	BK	<input type="checkbox"/> CWL1230R		

Industrial grade flanged inlets & outlets



Rating	A	V/AC	NEMA	Description	Color	Flanged inlet	Flanged outlet	
30	480	L12-30	3Ø standard industrial		W	<input type="checkbox"/> CWL1230FI	—	
			3Ø standard industrial		W	—	<input type="checkbox"/> CWL1230FO ^A	•

^ANot CSA certified

Accessories for NEMA L12-30 locking devices

Description	Catalog no.	
Diecast aluminum single receptacle cover, vertical mount, for FS/FD boxes	<input type="checkbox"/> 7420	
Glass-filled nylon flanged inlet/outlet cover, vertical mount, for 30A devices	<input type="checkbox"/> WP2	• •



7420



WP2

Color information:

BK (Black), W (White)



Dimensional information:
C-77, C-78

Receptacle specification information:
L12-30: C-87

Compliances, specifications and availability are subject to change without notice.