



### Hart lock industrial grade 50A locking devices

#### Product description

2-pole, 3-wire grounding  
 50A, 250V/AC  
 Non-NEMA, California standard

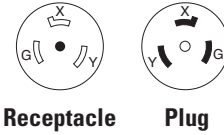

CS8265

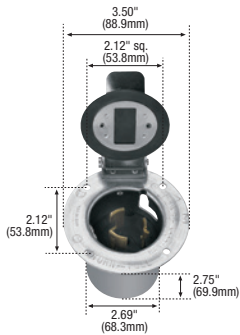

CS8277

#### California standard plugs & connectors

Rating	A	V/AC	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
50	250		Pro grip nylon California standard	0.44-1.06" (11.1-26.0mm)	RD & BK	<input type="checkbox"/> CS8265EX	<input type="checkbox"/> CS8264EX		
			Armored California standard	0.68-1.13" (17.3-28.6mm)	Steel	<input type="checkbox"/> CS8265	<input type="checkbox"/> CS8264		

#### California standard grade receptacles

Rating	A	V/AC	Description	Color	Single receptacle		
50	250		California standard receptacles	BK	<input type="checkbox"/> CS8269		

#### California standard flanged inlets

Rating	A	V/AC	Description	Color	Flanged inlet	Flanged inlet w/ lid		
50	250		California standard flanged inlets	Steel	<input type="checkbox"/> CS8275	<input type="checkbox"/> CS8277		

#### Accessories for 50A California standard locking devices

Description	Color suffix	Catalog no.		
Weather protective glass-filled nylon, w/ lift lid cover	BK, CR, GY	<input type="checkbox"/> 7788__		
Weather protective diecast aluminum, w/ lift lid cover		<input type="checkbox"/> 7770		
Weather protective boot for 50A armored plug		<input type="checkbox"/> 7716		
Weather protective boot for 50A armored connector		<input type="checkbox"/> 7717		
Weather protective boot for 50A pro grip plug		<input type="checkbox"/> 7716EX		
Weather protective boot for 50A pro grip connector		<input type="checkbox"/> 7717EX		



7788CR  
Corrosion resistant



7770



7716



7717



7716EX



7717EX

#### Dimensional information:

C-80, C-81

#### Plug & connector specification information:

50A pro grip: C-92  
 50A armored: C-92

#### Receptacle specification information:

 
50A: C-92

#### Flanged inlet & flanged outlet specification information:

50A: C-92

#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: BK (Black), GY (Gray), RD (Red), Y or CR (Yellow)



Compliances, specifications and availability are subject to change without notice.