


Hart lock industrial grade 50A locking devices

Product description

3-pole, 4-wire grounding
50A, 250V/DC / 600V/AC
Non-NEMA

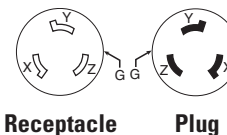

Receptacle

Plug

Industrial grade plugs & connectors



A	Rating V/DC	V/AC	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
50	250	600	Pro grip nylon	0.44-1.06" (11.1-26.0mm)	RD & BK	□ 3765EX	□ 3764EX	•	•
			Armored	0.68-1.13" (17.3-28.6mm)	Steel	□ 3765	□ 3764	•	•

Industrial grade receptacles



A	Rating V/DC	V/AC	Description	Color	Single receptacle		
50	250	600	Receptacles	BK	□ 3769	•	•

Industrial grade flanged inlets



A	Rating V/DC	V/AC	Description	Color	Flanged inlet		Flanged inlet w/ lid	
50	250	600	Flanged inlets	Steel	□ 3775	•	□ 3768	•

Accessories for 50A industrial grade locking devices


Description	Color suffix	Catalog no.		
Weather protective glass-filled nylon, w/ lift lid cover	BK, CR, GY	□ 7788	•	•
Weather protective diecast aluminum, w/ lift lid cover		□ 7770		•
Weather protective boot for 50A armored plug		□ 7716		•
Weather protective boot for 50A armored connector		□ 7717		•
Weather protective boot for 50A pro grip plug		□ 7716EX		•
Weather protective boot for 50A pro grip connector		□ 7717EX		•




3765



3764

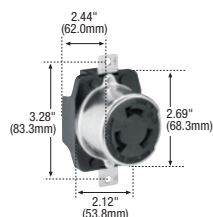

3769

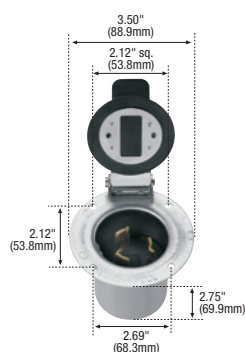

3768

7788CR
Corrosion
resistant

7770



7716



7717



7716EX



7717EX

Dimensional information:
C-80, C-81Plug & connector specification
information:

50A pro grip: C-92
50A armored: C-92

Receptacle specification
information:

50A: C-92

Flanged inlet & flanged outlet
specification information:

50A: C-92

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: BK (Black), GY (Gray), RD (Red), Y or CR (Yellow)

(Black)	(Gray)	(Red)	(Yellow)	(Steel)

Compliances, specifications and availability are subject to change without notice.



Indicates NAFTA compliant - Page Q-30



RoHS compliant - Page Q-30