

# D

SECTION

## Hart lock locking devices

### Hart lock complex environment locking devices

#### Product description

2-pole, 3-wire grounding  
15A, 277V/AC  
NEMA L7-15



L7-15R




L7-15P


#### Hart lock plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	277	L7-15	Watertight	0.30-0.65" (7.6-16.5mm)	Y	□ 24W34	□ 25W34	•	•
			Watertight	0.30-0.65" (7.6-16.5mm)	BK	□ 24W34BK	□ 25W34BK	•	•

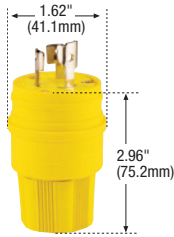

24W34

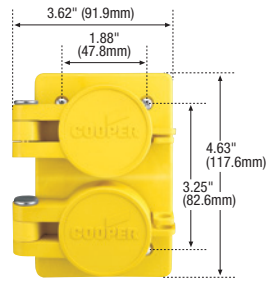

65W34DPLX

#### Hart lock receptacles



Rating A	V/AC	NEMA	Description	Color	Single receptacle catalog no.	Duplex receptacle catalog no.		
15	277	L7-15	Watertight	Y	□ 65W34	□ 65W34DPLX	•	•
			Watertight	BK	□ 65W34BK	□ 65W34DPLXBK	•	•

### Hart lock complex environment locking devices

#### Product description

2-pole, 3-wire grounding  
20A, 125V/AC  
NEMA L5-20



L5-20R




L5-20P

#### Hart lock plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	125	L5-20	Watertight	0.36-0.84" (9.1-21.3mm)	Y	□ L520PW	□ L520CW	•	•
			Watertight	0.36-0.84" (9.1-21.3mm)	BK	□ L520PWBK	□ L520CWBK	•	•
			Severe duty	0.38-1.00" (9.5-25.4mm)	Y & BK	□ L520PY	□ L520CY	•	•
			Safety grip corrosion resistant	0.38-1.00" (9.5-25.4mm)	Y	□ CRL520P	□ CRL520C	•	•

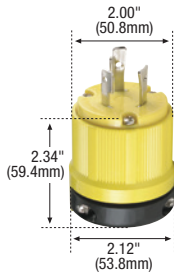

CRL520P

#### Hart lock receptacles



Rating A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
20	125	L5-20	Watertight	Y	□ L520RW <sup>Δ</sup> *	•	•
			Watertight	BK	□ L520RWBK <sup>Δ</sup> *	•	•
			Corrosion resistant	Y	□ CRL520R	•	•

 
\*Not Fed Spec, <sup>Δ</sup> cULus Listed

**Dimensional information:**  
D-34-35

**Specification information:**  
Watertight industrial plugs & connectors: D-38  
Watertight industrial receptacles: D-39  
Severe duty industrial plugs & connectors: D-40  
Corrosion resistant: D-41

#### Color information:

BK (Black), Y (Yellow)



**Compliances, specifications and availability are subject to change without notice.**