

# D

SECTION

## Hart lock locking devices

### Hart lock complex environment locking devices

#### Product description

2-pole, 3-wire grounding  
20A, 480V/AC  
NEMA L8-20




L8-20R

L8-20P



CRL530C

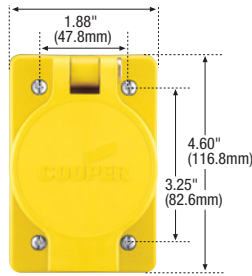

L530RW

#### Hart lock plugs & connectors



Rating	A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	480	L8-20	Watertight	0.36-0.84" (9.1-21.3mm)	Y	□ L820PW	□ L820CW	•	•	
			Watertight	0.36-0.84" (9.1-21.3mm)	BK	□ L820PWBK	□ L820CWBK	•	•	
			Severe duty	0.38-1.00" (9.5-25.4mm)	Y & BK	□ L820PY	□ L820CY	•	•	

#### Hart lock receptacles



Rating	A	V/AC	NEMA	Description	Color	Single receptacle catalog no.	
20	480	L8-20	Watertight	Y	□ L820RW	•	
			Watertight	BK	□ L820RWBK	•	

### Hart lock complex environment locking devices

#### Product description

2-pole, 3-wire grounding  
30A, 125V/AC  
NEMA L5-30



L5-30R

L5-30P

#### Hart lock plugs & connectors



Rating	A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
30	125	L5-30	Watertight	0.43-1.15" (10.9-29.2mm)	Y	□ L530PW	□ L530CW	•	•	
			Watertight	0.43-1.15" (10.9-29.2mm)	BK	□ L530PWBK	□ L530CWBK	•	•	
			Severe duty	0.38-1.00" (9.5-25.4mm)	Y & BK	□ L530PY	□ L530CY	•	•	
			Safety grip corrosion resistant	0.38-1.00" (9.5-25.4mm)	Y	□ CRL530P	□ CRL530C	•	•	

#### Hart lock receptacles



Rating	A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
30	125	L5-30	Watertight	Y	□ L530RW*	•	•	
			Watertight	BK	□ L530RWBK*	•	•	
			Corrosion resistant	Y	□ CRL530R	•	•	

\* Not Fed Spec

#### Dimensional information:

D-34-35

#### Specification information:

Watertight industrial plugs & connectors: D-38  
Watertight industrial receptacles: D-39  
Severe duty industrial plugs & connectors: D-40  
Corrosion resistant: D-41

#### Color information:

BK (Black), Y (Yellow)



(Black)



(Yellow)

Compliances, specifications and availability are subject to change without notice.