 


Hart lock locking devices

Hart lock complex environment locking devices

Product description

2-pole, 3-wire grounding
30A, 250V/AC
NEMA L6-30




L6-30R

L6-30P



L630PW

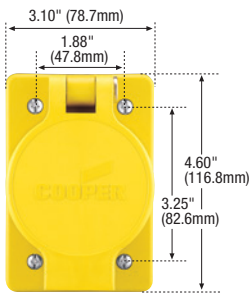

L730RW

Hart lock plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
30	250	L6-30	Watertight	0.43-1.15" (10.9-29.2mm)	Y	<input type="checkbox"/> L630PW	<input type="checkbox"/> L630CW	•	•
			Watertight	0.43-1.15" (10.9-29.2mm)	BK	<input type="checkbox"/> L630PWBK	<input type="checkbox"/> L630CWBK	•	•
			Severe duty	0.38-1.00" (9.5-25.4mm)	Y & BK	<input type="checkbox"/> L630PY	<input type="checkbox"/> L630CY	•	•
			Safety grip corrosion resistant	0.38-1.00" (9.5-25.4mm)	Y	<input type="checkbox"/> CRL630P	<input type="checkbox"/> CRL630C	•	•

Hart lock receptacles

 


Rating A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
30	250	L6-30	Watertight	Y	<input type="checkbox"/> L630RW	•	•
			Watertight	BK	<input type="checkbox"/> L630RWBK	•	•
			Corrosion resistant	Y	<input type="checkbox"/> CRL630R	•	•

Hart lock complex environment locking devices

Product description

2-pole, 3-wire grounding
30A, 277V/AC
NEMA L7-30



L7-30R

L7-30P

Hart lock plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
30	277	L7-30	Watertight	0.43-1.15" (10.9-29.2mm)	Y	<input type="checkbox"/> L730PW	<input type="checkbox"/> L730CW	•	•
			Watertight	0.43-1.15" (10.9-29.2mm)	BK	<input type="checkbox"/> L730PWBK	<input type="checkbox"/> L730CWBK	•	•
			Severe duty	0.38-1.00" (9.5-25.4mm)	Y & BK	<input type="checkbox"/> L730PY	<input type="checkbox"/> L730CY	•	•

Hart lock receptacles



Rating A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
30	277	L7-30	Watertight	Y	<input type="checkbox"/> L730RW	•	•
			Watertight	BK	<input type="checkbox"/> L730RWBK	•	•

Dimensional information:
D-34-35

Specification information:
Watertight industrial plugs & connectors: D-38
Watertight industrial receptacles: D-39
Severe duty industrial plugs & connectors: D-40
Corrosion Resistant: D-41

Color information:

BK (Black), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.