

D

 
SECTION

Hart lock locking devices

Hart lock complex environment locking devices


Product description

4-pole, 4-wire non-grounding
20A, 3ØY 277/480V/AC
NEMA L19-20




L19-20R

L19-20P

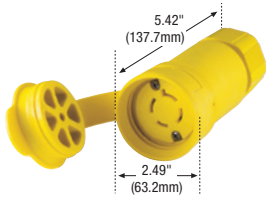

L1920CW

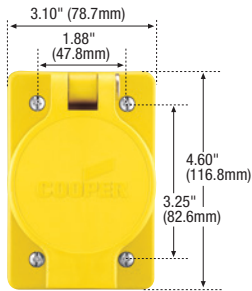

L1920RW

Hart lock 3ØY plugs & connectors



Rating									
A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	277/480	L19-20	3ØY watertight	0.36-0.84" (9.1-21.3mm)	Y	□ L1920PW	□ L1920CW	•	•
			3ØY watertight	0.36-0.84" (9.1-21.3mm)	BK	□ L1920PWBK	□ L1920CWBK	•	•
			3ØY severe duty	0.63-1.16" (15.9-29.4mm)	Y & BK	□ L1920PY	□ L1920CY	•	•

Hart lock 3ØY receptacles




Rating									
A	V/AC	NEMA	Description	Color	Single receptacle catalog no.				
20	277/480	L19-20	3ØY watertight	Y	□ L1920RW	•	•		
			3ØY watertight	BK	□ L1920RWBK	•	•		

Hart lock complex environment locking devices

Product description

 4-pole, 4-wire non-grounding
20A, 3ØY 347/600V/AC
NEMA L20-20



L20-20R

L20-20P

Hart lock 3ØY plugs & connectors



Rating									
A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	347/600	L20-20	3ØY watertight	0.36-0.84" (9.1-21.3mm)	Y	□ L2020PW	□ L2020CW	•	•
			3ØY watertight	0.36-0.84" (9.1-21.3mm)	BK	□ L2020PWBK	□ L2020CWBK	•	•
			3ØY severe duty	0.63-1.16" (15.9-29.4mm)	Y & BK	□ L2020PY	□ L2020CY	•	•

Hart lock 3ØY receptacles




Rating									
A	V/AC	NEMA	Description	Color	Single receptacle catalog no.				
20	347/600	L20-20	3ØY watertight	Y	□ L2020RW	•			
			3ØY watertight	BK	□ L2020RWBK	•			

Dimensional information:
D-34-35

Specification information:
Watertight industrial plugs & connectors: D-38
Watertight industrial receptacles: D-39
Severe duty industrial plugs & connectors: D-40

Color information:

 BK (Black), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.