
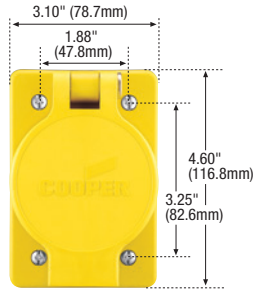


Hart lock complex environment locking devices

Product description

4-pole, 4-wire non-grounding
30A, 3ØY 277/480V/AC
NEMA L19-30

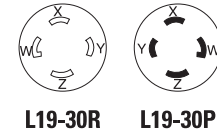

L2030RW

Hart lock 3ØY plugs & connectors

Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
30	277/ 480	L19-30	3ØY watertight	0.43-1.15" (10.9-29.2mm)	Y	□ L1930PW	□ L1930CW	•	•
			3ØY watertight	0.43-1.15" (10.9-29.2mm)	BK	□ L1930PWBK	□ L1930CWBK	•	•
			3ØY severe duty	0.63-1.16" (15.9-29.4mm)	Y & BK	□ L1930PY	□ L1930CY	•	•


Hart lock 3ØY receptacles

Rating A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
30	277/ 480	L19-30	3ØY watertight	Y	□ L1930RW	•	•
			3ØY watertight	BK	□ L1930RWBK	•	•

Hart lock complex environment locking devices

Product description

4-pole, 4-wire non-grounding
30A, 3ØY 347/600V/AC
NEMA L20-30

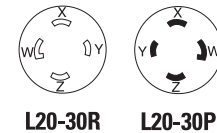

Hart lock 3ØY plugs & connectors

Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
30	347/ 600	L20-30	3ØY watertight	0.43-1.15" (10.9-29.2mm)	Y	□ L2030PW	□ L2030CW	•
			3ØY watertight	0.43-1.15" (10.9-29.2mm)	BK	□ L2030PWBK	□ L2030CWBK	•
			3ØY severe duty	0.63-1.16" (15.9-29.4mm)	Y & BK	□ L2030PY	□ L2030CY	•

Hart lock 3ØY receptacles


Rating A	V/AC	NEMA	Description	Color	Single receptacle catalog no.		
30	347/ 600	L20-30	3ØY watertight	Y	□ L2030RW	•	•
			3ØY watertight	BK	□ L2030RWBK	•	•

Dimensional information:
D-34-35

Specification information:
Watertight industrial plugs & connectors: D-38
Watertight industrial receptacles: D-39
Severe duty industrial plugs & connectors: D-40

Color information:

 BK (Black), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-30

RoHS compliant - Page Q-30