
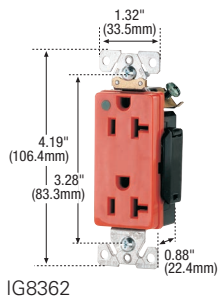
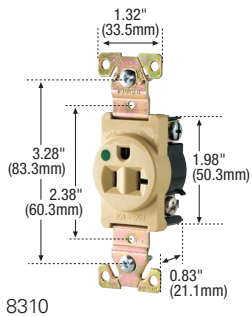
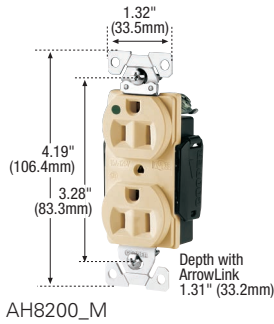
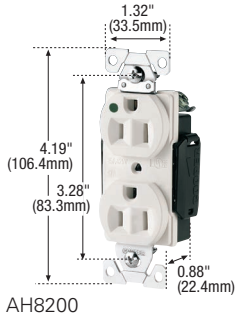


Hospital grade receptacles

Hospital grade straight blade receptacles

Product description

2-pole, 3-wire grounding
 15A, 125V/AC; 20A, 125V/AC
 NEMA 5-15R, 5-20R

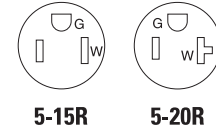

Premium hospital grade receptacles




Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.	▶	◀	USA	✓
15	125	5-15R	Premium duplex receptacle, back & side wire		B, GY, RD, V, W	□ AH8200__	•	•	•	•
			Premium illuminated duplex receptacle, back & side wire		V, W	□ AH8200LT__	•	•	•	•
			Premium single receptacle, back & side wire		B, GY, V, W	□ 8210__*	•	•	•	•
20	125	5-20R	Premium duplex receptacle, back & side wire		B, BK, GY, LA, RD, V, W	□ AH8300__	•	•	•	•
			Premium illuminated duplex receptacle, back & side wire		RD, V	□ AH8300LT__	•	•	•	•
			Premium single receptacle, back & side wire		B, RD, V, W	□ 8310__	•	•	•	•

Premium decorator hospital grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.	▶	◀	USA	✓
15	125	5-15R	Premium decorator duplex receptacle, back & side wire		GY, RD, V, W	□ 8262__	•	•	•	•
			Premium decorator illuminated duplex receptacle, back & side wire		V, W	□ 8262LT__	•	•	•	•
20	125	5-20R	Premium decorator duplex receptacle, back & side wire		B, BK, GY, RD, V, W	□ 8362__	•	•	•	•
			Premium decorator illuminated duplex receptacle, back & side wire		RD, V, W	□ 8362LT__	•	•	•	•

 Isolated ground premium hospital grade receptacles




Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.	▶	◀	USA	✓
15	125	5-15R	Premium IG duplex receptacle, back & side wire		GY, RD, RN, V, W	□ IG8200__	•	•	•	•
			Premium IG single receptacle, back & side wire		RN	□ IG8210__*	•	•	•	•
			Premium IG decorator duplex receptacle, back & side wire		GY, RN, V, W	□ IG8262__*	•	•	•	•
20	125	5-20R	Premium IG duplex receptacle, back & side wire		GY, RD, RN, V, W	□ IG8300__	•	•	•	•
			Premium IG single receptacle, back & side wire		RN	□ IG8310__*	•	•	•	•
			Premium IG decorator duplex receptacle, back & side wire		GY, RN, V, W	□ IG8362__	•	•	•	•

*Not Fed Spec

Color ordering information:

 For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), V (Ivory), W (White)



Specification information: Premium HG receptacles: A-26, Isolated ground premium HG receptacles: A-27, ArrowLink premium HG Receptacles: A-30 & A-31,

Compliances, specifications and availability are subject to change without notice.

▶ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page A-5

◀ Build-to-spec customizable devices - Page A-6

USA Indicates NAFTA compliant - Page Q-30

✓ RoHS compliant - Page Q-30