








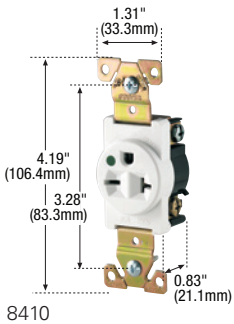

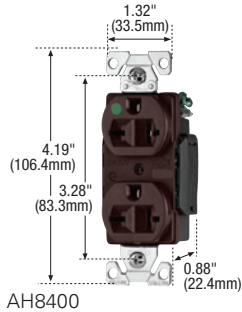

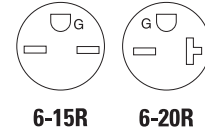










Hospital grade straight blade receptacles

Product description

2-pole, 3-wire grounding
 15A, 250V/AC;
 20A, 250V/AC
 NEMA 6-15R, 6-20R












Premium hospital grade receptacles

Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	250	6-15R	Premium duplex receptacle, back & side wire	V, W	□ AH8600__				
			Premium single receptacle, back & side wire	V, W	□ 8610__				
20	250	6-20R	Premium duplex receptacle, back & side wire	B, GY, RD, V, W	□ AH8400__				
			Premium single receptacle, back & side wire	B, RD, V, W	□ 8410__				

Isolated ground premium hospital grade receptacles

Rating	A	V/AC	NEMA	Description	Color	Catalog no.		
20	250	6-20R	Premium IG duplex receptacle, back & side wire	RN	□ IG8400RN			

Accessories for hospital grade NEMA 6-15 & 6-20 receptacles

Description	Color suffix	Catalog no.		
1-Gang, standard size duplex receptacle nylon wallplate	A, B, BK, GY, LA, RD, V, W	□ 5132__		
1-Gang, standard size single receptacle wallplate, CuVerro®	CU, CUR	□ 93091__		
1-Gang, mid-size duplex receptacle polycarbonate wallplate	A, B, BK, BL, GY, LA, RD, V, W	□ PJ8__		
1-Gang, standard size duplex receptacle wallplate, CuVerro®	CU, CUR	□ 93101__		



5132V



93091CU



PJ8LA



93101CUR


Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), BL (Blue), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), V (Ivory), W (White), CU (White Bronze) CuVerro® ONLY, CUR (Rose) CuVerro® ONLY

A	B	BK	BL	GY	LA	RD	RN	V
(Almond)	(Brown)	(Black)	(Blue)	(Gray)	(Lt. Almond)	(Red)	(Orange)	(Ivory)
W	CU	CUR						
(White)	(White Bronze)	(Rose)						

Specification information: Premium HG receptacles: A-26, ArrowLink premium HG receptacles: A-30 & A-31, Isolated ground premium HG receptacles: A-27, CuVerro® wallplates: K-22

Compliances, specifications and availability are subject to change without notice

 ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page A-5

 Build-to-spec customizable devices - Page A-6

 Indicates NAFTA compliant - Page Q-30

 RoHS compliant - Page Q-30