




SECTION

Manual motor controllers

Industrial grade manual motor controllers

Product description

2-pole
 10/20A, 250/125V/AC or DC
 20/30A, 250/125V/AC or DC
 20/30A, 600/250V/AC

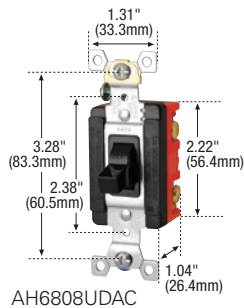

AH6808UDAC



AH6808GDAC

Three-position, maintained contact, double throw, 2-pole, single-phase



Rating A	V/AC/DC	Description	Termination style	Max. AWG wire size	Catalog no.
10	250	Switch, center "off", black	Side wired screw	#10 AWG	□ AH4361
20	125	Switch, center "off", in NEMA type 1 enclosure	Side wired screw	#10 AWG	□ AH27940G

Horsepower rated for motor loads per UL508

	240 V/AC	250 V/AC/DC	250 V/DC
HP 2	—	—	1.5

Two-position, maintained contact, single throw, 2-pole, single-phase



Rating A	V/AC	Description	Termination style	Max. AWG wire size	Catalog no.		
20	600	Switch only	Back & side wired screw	#10 AWG	□ AH6808UDAC	•	•
30	250	Switch with cover plate for flush mounting	Back & side wired screw	#10 AWG	□ AH6808FDAC	•	•
		Switch in NEMA 1 enclosure	Back & side wired screw	#10 AWG	□ AH6808GDAC	•	•
		Switch in NEMA type 3R copperless aluminum enclosure	Back & side wired screw	#10 AWG	□ AH6808WDAC	•	•

Horsepower rated for motor loads per UL508

	120 V/AC	240 V/AC	480 V/AC	600 V/AC
HP 2	3	3	5	7.5

Specification information: AH6800 series: E-45

Compliances, specifications and availability are subject to change without notice.



Indicates NAFTA compliant - Page Q-30



RoHS compliant - Page Q-30