
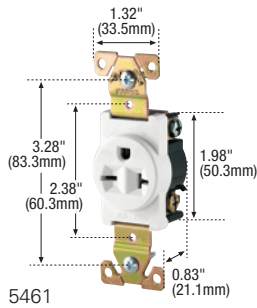
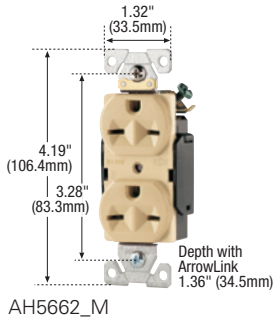


Industrial grade receptacles

Industrial grade straight blade receptacles

Product description

2-pole, 3-wire grounding
 15A, 250V/AC;
 20A, 250V/AC
 NEMA 6-15R, 6-20R

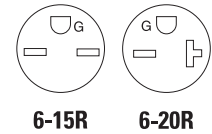

Premium industrial grade receptacles

Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	250	6-15R	Premium duplex receptacle, back & side wire		B, V, W	□ AH5662__				
			Premium single receptacle, back & side wire		B, V, W	□ 5661__				
20	250	6-20R	Premium duplex receptacle, back & side wire		B, GY, V, W	□ AH5462__				
			Premium single receptacle, back & side wire		B, GY, V, W	□ 5461__				

Premium decorator industrial grade receptacles

Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	250	6-15R	Premium decorator duplex receptacle, back & side wire		V, W	□ 6662__ [†]			
20	250	6-20R	Premium decorator duplex receptacle, back & side wire		V, W	□ 6462__			

[†] Not NOM cert

Isolated ground premium industrial grade receptacles

Rating	A	V/AC	NEMA	Description	Color	Catalog no.			
15	250	6-15R	Premium IG duplex receptacle, back & side wire		RN	□ AHIG5662RN			
			Premium IG single receptacle, back & side wire		RN	□ IG5661RN*			
20	250	6-20R	Premium IG duplex receptacle, back & side wire		RN	□ AHIG5462RN			
			Premium IG single receptacle, back & side wire		RN	□ IG5461RN*			

* Not Fed Spec

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), GY (Gray), RN (Orange), V (Ivory), W (White)



Specification information: ArrowLink premium industrial receptacles: A-32, Premium industrial receptacles: A-33, Premium decorator industrial receptacles: A-33, Isolated ground premium industrial receptacles: A-34

Compliances, specifications and availability are subject to change without notice.