 


# Surge protection receptacles

## Surge protection receptacles with LED indicators & audible alarm


### Product description

2-pole, 3-wire grounding  
15A, 125V/AC; 20A, 125V/AC; NEMA 5-15R & 5-20R




5-15R


5-20R

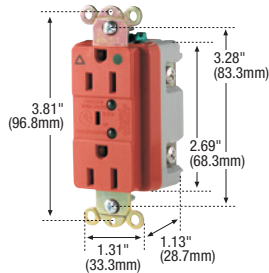


IG8200HG\_S

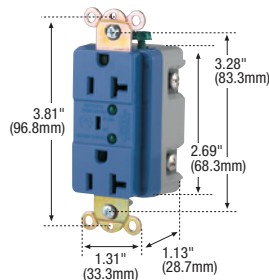

5362\_S

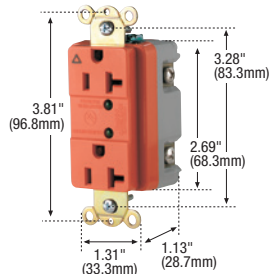

IG5350\_S

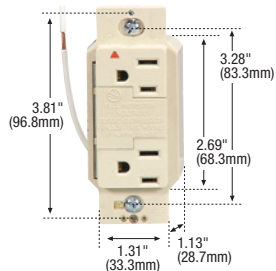

IG1208



1209

### Receptacles w/audible alarm & LED indicators, back & side wire



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.		
15	125	5-15R	Hospital grade, duplex receptacle	BL, GY, RD, V, W	□ 8200__S	▶	◀	
			IG hospital grade, duplex receptacle	BL, GY, RN, V, W	□ IG8200HG__S	▶	◀	
			Commercial grade, duplex receptacle	BL, GY, V, W	□ 5262__S	▶	◀	
			IG commercial grade, duplex receptacle	BL, GY, RN, V, W	□ IG5262__S	▶	◀	
20	125	5-20R	Hospital grade, duplex receptacle	BL, GY, RD, V, W	□ 8300__S	▶	◀	
			IG hospital grade, duplex receptacle	BL, GY, RN, V, W	□ IG8300HG__S	▶	◀	
			Commercial grade, duplex receptacle	BL, GY, V, W	□ 5362__S	▶	◀	
			IG commercial grade, duplex receptacle	BL, GY, RN, V, W	□ IG5362__S	▶	◀	

560 Joules, max. surge current - 18kA per mode

### Receptacles w/LED indicators, back & side wire



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.		
15	125	5-15R	Commercial grade, duplex receptacle	BL, GY, V, W	□ 5250__S	▶	◀	
			IG commercial grade, duplex receptacle	BL, GY, RN, V, W	□ IG5250__S	▶	◀	
20	125	5-20R	Commercial grade, duplex receptacle	BL, GY, V, W	□ 5350__S	▶	◀	
			IG commercial grade, duplex receptacle	BL, GY, RN, V, W	□ IG5350__S	▶	◀	

840 Joules, max. surge current - 18kA per mode

 
### Receptacles w/audible alarm



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.		
15	125	5-15R	Commercial grade, duplex receptacle	V, W	□ 1208__	▶	◀	
			IG commercial grade, duplex receptacle	V, W	□ IG1208__	▶	◀	
20	125	5-20R	Commercial grade, duplex receptacle	BL, V, W	□ 1210__	▶	◀	
			IG commercial grade, duplex receptacle	V, W	□ IG1210__	▶	◀	

340 Joules, max. surge current - 12kA per mode

### Replacement surge bloc module



Description	Color suffix	Catalog no.
Replacement module	A, BL, GY, V, W	□ 1209__

### Accessories for surge protection receptacles



Description	Color	Catalog no.
1-Gang mid-size decorator polycarbonate wallplate	BL	□ PJ26BL
1-Gang mid-size decorator polycarbonate wallplate	W	□ PJ26W
1-Gang mid-size decorator polycarbonate wallplate, pre-marked "ISOLATED GROUND"	RN	□ PJ26IG

### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: BL (Blue), GY (Gray), RD (Red), RN (Orange), V (Ivory), W (White)

BL	GY	RD	RN	V	W
(Blue)	(Gray)	(Red)	(Orange)	(Ivory)	(White)

**Specification information:** Surge protection receptacles with audible alarm & LED I-20; surge protection receptacles with LED indicators I-21

**Compliances, specifications and availability are subject to change without notice.**