

## J


SECTION

## Straight blade receptacles

## Hospital grade straight blade receptacles

## Product description

2-pole, 3-wire grounding  
15A, 125V/AC; 20A, 125V/AC  
NEMA 5-15R, 5-20R

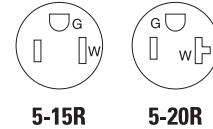

5-15R

5-20R

## Premium hospital grade receptacles



 
| Rating<br>A | V/AC | NEMA  | Description                                     | Color suffix            | Catalog no.  |   |   |   |
|-------------|------|-------|-------------------------------------------------|-------------------------|--------------|---|---|---|
| 15          | 125  | 5-15R | Duplex receptacle, back & side wire             | B, GY, RD, V, W         | □ AH8200__   | • | • | • |
|             |      |       | Illuminated duplex receptacle, back & side wire | V, W                    | □ AH8200LT__ | • | • | • |
|             |      |       | Single receptacle, back & side wire             | B, GY, V, W             | □ 8210       | • | • | • |
| 20          | 125  | 5-20R | Duplex receptacle, back & side wire             | B, BK, GY, LA, RD, V, W | □ AH8300__   | • | • | • |
|             |      |       | Illuminated duplex receptacle, back & side wire | RD, V                   | □ AH8300LT__ | • | • | • |
|             |      |       | Single receptacle, back & side wire             | B, RD, V, W             | □ 8310__     | • | • | • |

## Premium decorator hospital grade receptacles



| Rating<br>A | V/AC | NEMA  | Description                                     | Color suffix        | Catalog no. |   |   |   |
|-------------|------|-------|-------------------------------------------------|---------------------|-------------|---|---|---|
| 15          | 125  | 5-15R | Duplex receptacle, back & side wire             | GY, RD, V, W        | □ 8262__    | • | • | • |
|             |      |       | Illuminated duplex receptacle, back & side wire | V, W                | □ 8262LT__  | • | • | • |
| 20          | 125  | 5-20R | Duplex receptacle, back & side wire             | B, BK, GY, RD, V, W | □ 8362__    | • | • | • |
|             |      |       | Illuminated duplex receptacle, back & side wire | RD, V, W            | □ 8362LT__  | • | • | • |

## Isolated ground premium hospital grade receptacles



| Rating<br>A | V/AC | NEMA  | Description                                      | Color suffix     | Catalog no. |   |   |   |
|-------------|------|-------|--------------------------------------------------|------------------|-------------|---|---|---|
| 15          | 125  | 5-15R | IG duplex receptacle, back & side wire           | GY, RD, RN, V, W | □ IG8200__  | • | • | • |
|             |      |       | IG single receptacle, back & side wire           | RN               | □ IG8210*   |   |   | • |
|             |      |       | IG decorator duplex receptacle, back & side wire | GY, RN, V, W     | □ IG8262__* | • | • | • |
| 20          | 125  | 5-20R | IG duplex receptacle, back & side wire           | GY, RD, RN, V, W | □ IG8300__  | • | • | • |
|             |      |       | IG single receptacle, back & side wire           | RN               | □ IG8310*   |   |   | • |
|             |      |       | IG decorator duplex receptacle, back & side wire | GY, RN, V, W     | □ IG8362__  | • | • | • |

\*Not Fed. Spec.

## USB charger with hospital grade tamper resistant receptacle



| Receptacle Rating<br>A | Rating<br>V/AC | USB Rating<br>Amp | Rating<br>V/DC | Description                                                        | Color Suffix     | Catalog No. |
|------------------------|----------------|-------------------|----------------|--------------------------------------------------------------------|------------------|-------------|
| 15                     | 125            | 2.1               | 5              | USB Charger with Hospital Grade Tamper Resistant Duplex Receptacle | GY, LA, RD, V, W | □ TR8245__  |
| 20                     | 125            | 2.1               | 5              | USB Charger with Hospital Grade Tamper Resistant Duplex Receptacle | GY, LA, RD, V, W | □ TR8345__  |

## Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), V (Ivory), W (White)

|         |         |        |              |       |          |         |         |
|---------|---------|--------|--------------|-------|----------|---------|---------|
| B       | BK      | GY     | LA           | RD    | RN       | V       | W       |
| (Brown) | (Black) | (Gray) | (Lt. Almond) | (Red) | (Orange) | (Ivory) | (White) |


Compliances, specifications and availability are subject to change without notice.

➤ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page J-2


➤ Build-to-spec customizable devices - Page J-4

➤ Indicates NAFTA compliant - Page Q-30


TR Tamper resistant

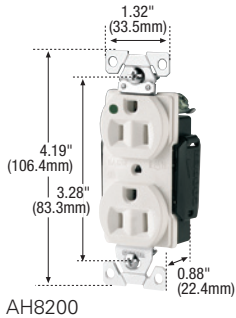


AH8200

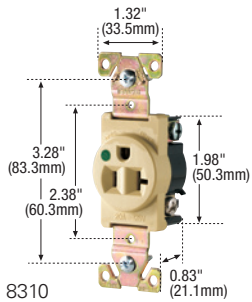

8310

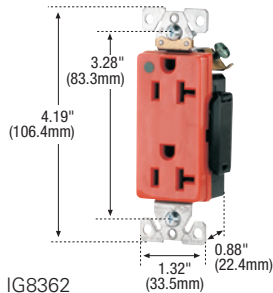

IG8362

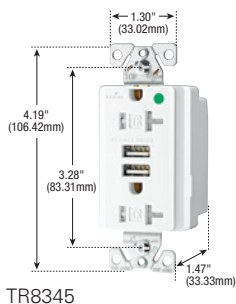

TR8345

## Specification information:

Premium HG receptacles: A-26  
ArrowLink premium HG  
Receptacles: A-30 & A-31  
Isolated ground premium HG  
receptacles: A-27