

J


SECTION

Straight blade receptacles

Hospital grade straight blade receptacles

Product description

2-pole, 3-wire grounding
15A, 250V/AC; 20A, 250V/AC
NEMA 6-15R, 6-20R

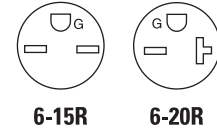

6-15R

6-20R


Premium hospital grade receptacles




Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	250	6-15R	Duplex receptacle, back & side wire		V, W	□ AH8600__	•	•	•
			Single receptacle, back & side wire		V, W	□ 8610__	•	•	
20	250	6-20R	Duplex receptacle, back & side wire		B, GY, RD, V, W	□ AH8400__	•	•	•
			Single receptacle, back & side wire		B, RD, V, W	□ 8410__	•	•	

Accessories for hospital grade NEMA 6-15 & 6-20 receptacles

Description	Color suffix	Catalog no.	
1-Gang standard size duplex receptacle nylon wallplate	V	□ 5132V	•
1-Gang standard size single receptacle wallplate, CuVerro®	CU	□ 93091CU	•
1-Gang mid-size duplex receptacle polycarbonate wallplate	LA	□ PJ8LA	
1-Gang standard size duplex receptacle wallplate, CuVerro®	CUR	□ 93101CUR	•

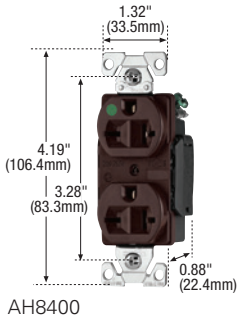

AH8400

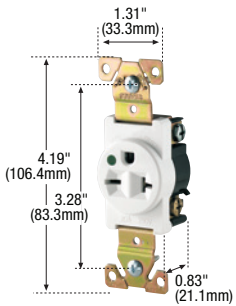

8410



5132V



93091CU



PJ8LA



93101CUR

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), GY (Gray), RD (Red), V (Ivory), W (White)



Specification information:

Premium HG receptacles: A-26
ArrowLink premium HG receptacles: A-30 & A-31
CuVerro® wallplates K-22

Compliances, specifications and availability are subject to change without notice.

➡ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page J-2

🇺🇸 Build-to-spec customizable devices - Page J-4

🇺🇸 Indicates NAFTA compliant - Page Q-30