

Weatherproof receptacle covers

Weatherproof covers for locking and straight blade receptacles

Product description

Nylon covers for FS/FD boxes


Weatherproof nylon covers for 15A, 20A & 30A devices

Features


- UL Listed for wet locations (cover closed) and damp locations (cover open or closed)
- Meets 2014 NEC® 406.9 (A) and 406.9 (B)(2)
- Rugged, glass-filled nylon provides high strength and wide temperature range for long life in abusive environments
- Easy mounting on FS/FD boxes or equipment panels
- Self-closing lift lid cover with neoprene gasket and stainless steel spring provides weatherproof protection
- Universal mounting holes to accept all Eaton's 15 & 20A and 30A locking flanged inlets and outlets, receptacles as well as devices with similar dimensions from other manufacturers



WP1

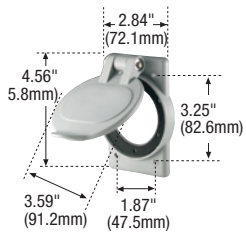

WP2

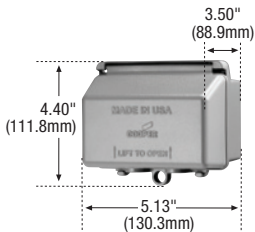


WIUMH-1



WIUM inserts

Glass-filled nylon covers

Description	Mtg. hole pattern	Color	Opening diameter	Catalog no.	
For 15 & 20A straight blade receptacles and 15A Hart lock flanged inlets & outlets	2 holes 180°, 2.09" (53.1mm) bolt dia. circle	GY	1.75" (44.45mm)	□ WP1*	•
For 20 & 30A Hart lock flanged inlets & outlets and 30 & 50A, 3-W straight blade receptacles	Two sets of 3 equally spaced holes: 3 holes on 2.5" (63.5mm) bolt dia. circle and 3 holes on 2.69" (68.3mm) bolt dia. circle	GY	2.25" (57.15mm)	□ WP2	•

* Not CSA certified

Metal weatherbox while-in-use weather protective covers

Product description


Metal 1-gang lockable cover boxes

Metal while-in-use cover boxes

Features

- Meets 2014 NEC® 406.9 (B)(1) for receptacles in damp or wet locations for one or two family dwellings
- Diecast powder coated aluminum
- NEMA 3R rating
- Comes with gasket, mounting hardware, duplex receptacle insert and GFCI receptacle insert
- Lockable to prevent accidental disconnects

Metal protective covers

Description	# of available config. using inserts	Color	Depth	Catalog no.	
Vertical mount	2	GY	3.25" deep (82.6mm)	□ WIUMV-1	•
Horizontal mount	2	GY	3.25" deep (82.6mm)	□ WIUMH-1	•

Color information:

GY (Gray)



(Gray)

Compliances, specifications and availability are subject to change without notice.