

# B

SECTION

## Industrial grade devices

### Industrial grade straight blade devices

#### Product description


2-pole, 3-wire grounding  
15A, 125V/AC  
NEMA 5-15



5-15P




5-15R

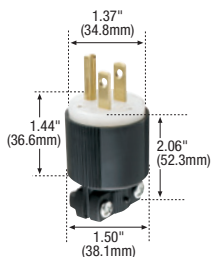

6266



AH5969BK

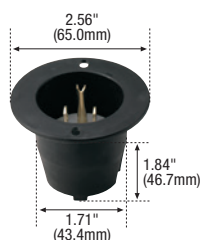

5278C



5278

#### Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	125	5-15	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH5266	<input type="checkbox"/> AH5269		
			Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK	<input type="checkbox"/> AH5266BK	<input type="checkbox"/> AH5269BK		
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH5266A	—		
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	BK	<input type="checkbox"/> AH5965BK	<input type="checkbox"/> AH5969BK		
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	Y	<input type="checkbox"/> AH5965Y	<input type="checkbox"/> AH5969Y		
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> 5266N	<input type="checkbox"/> 5269N		

#### Industrial grade flanged inlets & outlets



Rating A	V/AC	NEMA	Description	Color	Inlet catalog no.	Outlet catalog no.		
15	125	5-15	Nylon construction, back wire	BK & W	<input type="checkbox"/> AH5278C <sup>†</sup>	<input type="checkbox"/> AH5279C*		
			Metal shell, back wire	Steel	<input type="checkbox"/> AH5278	—		
			Metal shell, back wire	Steel	—	<input type="checkbox"/> AH5246*		

\* UL Listed only, <sup>†</sup> Fed Spec certified

**Industrial grade dimensional**  
Information: B-14, B-15

**Specification information:**  
Safety grip industrial plugs & connectors: B-22  
Quick grip plugs & connectors: B-22  
Auto grip industrial plugs & connectors: B-22  
Industrial flanged inlets & Flanged outlets: B-23

#### Color information:

BK (Black), W (White), Y (Yellow)



**Compliances, specifications and availability are subject to change without notice.**