
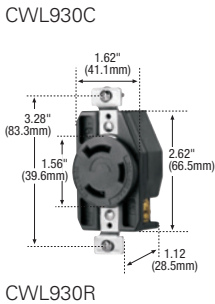
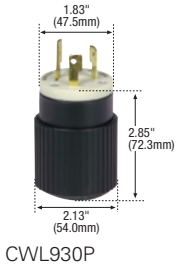


## Hart lock industrial grade 30A locking devices

### Product description

2-pole, 3-wire grounding  
30A, 600V/AC  
NEMA L9-30

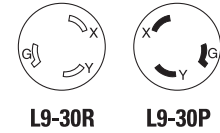

### Industrial grade plugs & connectors

Rating	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
30	600	L9-30	Straight body	0.30-0.95" (7.6-24.1mm)	BK & W	<input type="checkbox"/> CWL930P	<input type="checkbox"/> CWL930C	

### Industrial grade receptacles

Rating	V/AC	NEMA	Description	Color	Single receptacle	
30	600	L9-30	Standard industrial	BK	<input type="checkbox"/> CWL930R	

### Industrial grade flanged inlets & outlets

Rating	V/AC	NEMA	Description	Color	Flanged inlet	Flanged outlet	
30	600	L9-30	Standard industrial	W	<input type="checkbox"/> CWL930FI	—	
			Standard industrial	W	—	<input type="checkbox"/> CWL930FO <sup>††</sup>	

<sup>††</sup>Only UL Listed

### Accessories for NEMA 30A locking devices

Description	Catalog no.	
Die cast aluminum single receptacle cover, vertical mount, for FS/FD boxes	<input type="checkbox"/> 7420	
Glass-filled nylon flanged inlet/outlet cover, vertical mount, for 30A devices	<input type="checkbox"/> WP2 <sup>††</sup>	

<sup>††</sup>Only UL Listed



7420



WP2

### Color information:

BK (Black), W (White)



**Dimensional information:**  
C-77, C-78

**Receptacle specification information:**  
L9-30: C-87

Compliances, specifications and availability are subject to change without notice.