

Sign and Scoreboard Lighting

Attachon Lampholders,
Medium Base



Sign and Scoreboard Lampholders

FEATURES

- Insulation displacement terminals for stranded wire.
- Lay in wire channels, 1/4 turn twist top speeds installation.
- One piece terminals and contacts. No rivets or eyelets to loosen due to heat.
- Sockets are molded of heat-resistant phenolic.
- 732 is weatherproof – suitable for outdoor use.
- Snap-in or screw-in panel mounting options.
- Keyed spring washer prevents rotation of socket after installation.

Medium Base Attachon

Rating		Description	Wire Range	Mounting	Catalog No.
W	V				
660	250	Phenolic	#14 to #12	Hook	732
660	250	Phenolic	#14 to #12	No-Hook	732-1
660	250	Phenolic	#14 to #12	Snap-in	732-3
660	250	Phenolic	#18 to #12	Snap-in	4734-2
660	250	Phenolic	#14 to #12	Screws	734

Medium Base Attachon with Guard

Rating		Description	Wire Range	Mounting	Catalog No.
W	V				
200	250	Phenolic Socket Yellow Guard	#18 to #12	Hook	1466Y*



732



732-3



4734-2




734


*Not CSA certified

Panel Cutouts


732-3

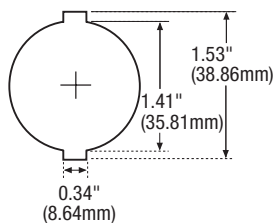

734

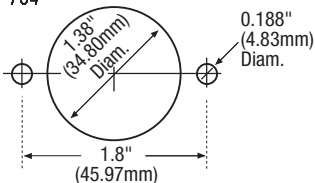

4734-2

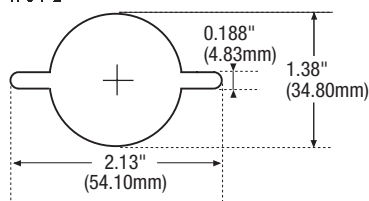

INDUSTRIAL
COMMERCIAL
RESIDENTIAL

R-8
LAMP HOLDERS

TESTING & CODE COMPLIANCE

- UL Listed, file E7430, UL 496 requirements
- CSA Certified, file 1739 (6231-07), Meet CSA requirements, C22.2 no. 43
- NOM Certified

MATERIAL CHARACTERISTICS

Temperature Rating:
-40°C to 65°C



Sign and Scoreboard Lighting

Attachon Lampholders,
Intermediate and
Candelabra Base

Sign and Scoreboard Lampholders

FEATURES

- Insulation displacement terminals for stranded wire.
- Lay in wire channels, 1/4 turn twist top speeds installation.
- One piece terminals and contacts. No rivets or eyelets to loosen due to heat.
- Sockets are molded of heat-resistant phenolic.
- Snap-in or screw-in panel mounting options.
- Keyed spring washer prevents rotation of socket after installation.



731



731-2



731-3



974-2

Intermediate Base Attachon

Rating		Description	Wire Range	Mounting	Catalog No.
W	V				
75	250	Phenolic	#18 to #16	Hook	731*
75	250	Phenolic	#18 to #16	No Hook	731-1
75	250	Phenolic	#18 to #16	Spring Washer	731-2
75	250	Phenolic	#18 to #16	Snap-in	731-3*

*CSA certified, file 1739


Candelabra Base Attachon

Rating		Description	Wire Range	Mounting	Catalog No.
W	V				
75	125	Phenolic	#20 to #18	No Hook	974**
75	125	Phenolic	#20 to #18	Spring Washer	974-2†


**CSA certified, file E21433

†Not CSA

Panel Cutouts 731-2, 731-3

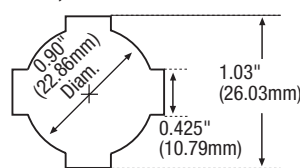

974-2

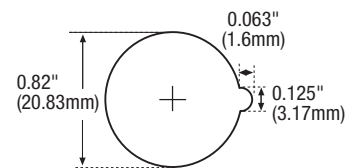

INDUSTRIAL
COMMERCIAL
RESIDENTIAL

R-9
LAMP HOLDERS

TESTING & CODE COMPLIANCE

- UL Listed, file E20152 or 26358, UL 496 requirements, Meet CSA requirements, C22.2 no. 43
- NOM Certified

MATERIAL CHARACTERISTICS

Temperature Rating:
-40°C to 65°C