



Decorator Commercial Specification Grade Straight Blade Receptacles

2P3W Grounding
15A 125V, 20A 125V


INDUSTRIAL
COMMERCIAL
RESIDENTIAL

B-7 DECORATOR DEVICES


Duplex and Single Receptacles

FEATURES

- Sturdy, compact design meets the demands of commercial spec grade performance.
- Excellent plug blade retention provided by triple-wipe 0.032" (0.81mm) triple-wipe brass line contacts and 0.050" (1.27mm) brass ground.
- High impact and chemical-resistant nylon face.
- 0.035" (0.89mm) galvanized steel, wrap-around yoke mounting strap for superior assembly security; extra length/width helps reach large panel cutouts for Code compliance.
- Automatic grounding system eliminates need for bonding jumper in grounded metal enclosure, provides redundant measure of ground continuity where jumper used.

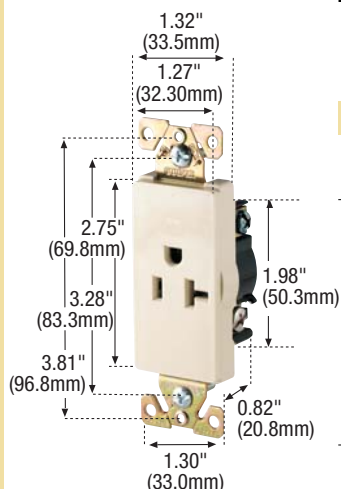

6350

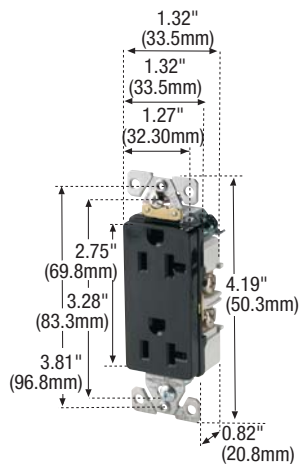

6352

Back and Side Wire

Rating A	V/AC	NEMA	Color	Catalog No.	
				Duplex	Single
15	125	5-15R	Almond	6252A	6250A
			Black	6252BK	6250BK
			Brown	6252B	6250B
			Gray	6252GY	6250GY
			Light Almond	6252LA	6250LA
			Red	—	6250RD
			Ivory	6252V	6250V
White	6252W	6250W			
20	125	5-20R	Almond	6352A	6350A
			Black	6352BK	6350BK
			Brown	6352B	6350B
			Gray	6352GY	6350GY
			Light Almond	6352LA	6350LA
			Red	—	6350RD
			Ivory	6352V	6350V
White	6352W	6350W			
15	250	6-15R	Almond	—	6650A
			Brown	—	6650B
			Ivory	—	6650V
			White	—	6650W
20	250	6-20R	Almond	—	6450A
			Brown	—	6450B
			Ivory	—	6450V
			White	—	6450W

TESTING & CODE COMPLIANCE

- UL Listed (file no. E15058).
- Meets all UL 498 requirements
- Meets all CSA requirements, C22.2 no.42 requirements
- CSA Certified (file no. 6914 (6233-01))
- NOM Certified.

MATERIAL CHARACTERISTICS

Flammability rating per UL94: V2 rated.
Temperature Rating:
-40°C to 70°C.



5-15R



5-20R