

Complex environment straight blade devices

Product description

2-pole, 3-wire grounding
20A, 250V/AC
NEMA 6-20




6-15P



6-15R

Plugs & connectors


Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	250	6-20	Watertight	0.30-0.65" (7.6-16.5mm)	Y	□ 14W48	□ 15W48	•	•
			Watertight	0.30-0.65" (7.6-16.5mm)	BK	□ 14W48BK	□ 15W48BK	•	•
			Severe duty	0.38-1.00" (19.1-25.4mm)	Y & BK	□ 1448	□ 1548	•	•

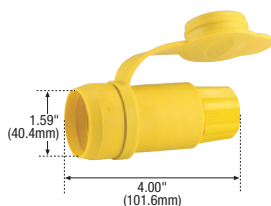


15W48

Watertight receptacles, back & side wire

Rating A	V/AC	NEMA	Description	Cord diameter	Color	Single receptacle catalog no.	Duplex receptacle catalog no.	
20	250	6-20	Watertight	0.30-0.65" (7.6-16.5mm)	Y	□ 60W48	□ 60W48BK	•
			Watertight	0.30-0.65" (7.6-16.5mm)	BK	□ 60W48DPLX	□ 60W48DPLXBK	•

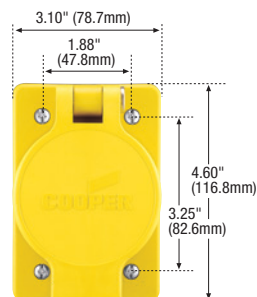

60W48

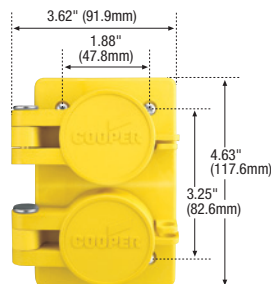

60W48DPLX

Accessories for watertight 20A plugs & connectors

Description	Cord diameter	Catalog no.		
Watertight plug closure cap for 15A plug, yellow		□ 14W	•	•
Watertight plug closure cap for 15A plug, black		□ 14WBK	•	•
Replacement watertight connector closure cap for 15A connector, yellow		□ 15W	•	•
Replacement watertight connector closure cap for 15A connector, black		□ 15WBK	•	•
Wire mesh grip for 15/20A watertight plugs & connectors	0.31-0.37" (7.9-9.5mm)	□ WTM131	•	•
Wire mesh grip for 15/20A watertight plugs & connectors	0.38-0.44" (9.5-11.1mm)	□ WTM138	•	•
Wire mesh grip for 15/20A watertight plugs & connectors	0.43-0.50" (10.9-12.7mm)	□ WTM143	•	•
Wire mesh grip for 15/20A watertight plugs & connectors	0.50-0.56" (12.7-14.3mm)	□ WTM150	•	•
Wire mesh grip for 15/20A watertight plugs & connectors	0.56-0.63" (14.3-15.9mm)	□ WTM156	•	•



14W



15W



WTM143

 
Dimensional information: D-9

Specification information:

Watertight industrial plugs & connectors: D-36
Watertight industrial receptacles: D-36
Severe duty industrial plugs & connectors: D-37

Color information:

BK (Black), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.

 Indicates NAFTA compliant - Page Q-30

 RoHS compliant - Page Q-30