

Z-Wave Plus wireless collection


Z-Wave Plus duplex receptacle

Product description

2-pole, 3-wire grounding
1/2 HP, 15A, 125V/AC



5-15R

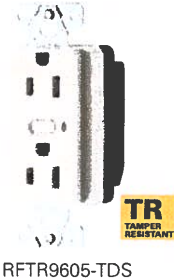

Design features

- For added safety, complies with NEC® specification that states all receptacles installed in dwelling units must be tamper resistant **TR TAMPER RESISTANT**
- Offers UL Listed safety shutter system that prevents insertion of foreign objects into receptacle
- Provides Z-Wave control of one outlet leaving the other one for normal use
- Ability to be controlled remotely by other Z-wave devices through association (Z-Wave Plus devices only)
- Can be wired with standard 3-way switch where traveler wire exist for 3-way
- Dimmable blue LED at center right of paddle illuminates to indicate ON/OFF status
- Patented built-in wire stripper for #14 and #12 wire to speed installation
- Patented indicator system alerts if the device is not set up in the network
- Rated for 1/2 HP motor loads
- Configurable "power ON state"
- Supports panic mode with compatible hubs
- Child lockout feature which disables local control at receptacle
- Available in 10 different colors including metallic finish
- Supports Z-Wave Plus functionality with S2 security certification

Z-Wave Plus wireless receptacle



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.
15	125	5-15R		Tamper resistant split control duplex receptacle, wire leads	AW, DS, WS, B, BK, LA, GY, RB, SG	<input type="checkbox"/> RFTR9605-T__

Complies with FCC Part 15, Class B; cULus Listed to UL38DS, file no. E325082; NOM certified

Color ordering information:

For ordering devices, include Catalog No. followed by the Color Suffix: AW (Alpine White), DS (Desert Sand), WS (White Satin), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RB (Oil Rubbed Bronze), SG (Silver Granite).

AW	AW	DS	DS	WS	WS
(Alpine White)		(Desert Sand)		(White Satin)	
B	BK	GY	LA	RB	SG
(Brown)	(Black)	(Gray)	(Light Almond)	(Oil Rubbed Bronze)	(Silver Granite)



Compliances, specifications and availability are subject to change without notice.

TR Tamper resistant