

### Industrial grade straight blade devices

#### Product description


2-pole, 3-wire grounding  
15A, 125V/AC  
NEMA 5-15



5-15P



5-15R

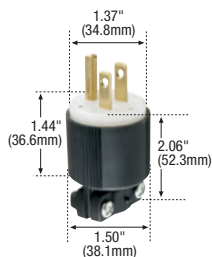

6266



AH5969BK



5278C



5278

#### Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	125	5-15	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH5266	<input type="checkbox"/> AH5269		
			Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK	<input type="checkbox"/> AH5266BK	<input type="checkbox"/> AH5269BK		
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH5266A	—		
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	BK	<input type="checkbox"/> AH5965BK	<input type="checkbox"/> AH5969BK		
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	Y	<input type="checkbox"/> AH5965Y	<input type="checkbox"/> AH5969Y		
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> 5266N	<input type="checkbox"/> 5269N		

#### Industrial grade flanged inlets & outlets



Rating A	V/AC	NEMA	Description	Color	Inlet catalog no.	Outlet catalog no.		
15	125	5-15	Nylon construction, back wire	BK & W	<input type="checkbox"/> AH5278C <sup>†</sup>	<input type="checkbox"/> AH5279C*		
			Metal shell, back wire	Steel	<input type="checkbox"/> AH5278	—		
			Metal shell, back wire	Steel	—	<input type="checkbox"/> AH5246*		

\* UL Listed only, <sup>†</sup> Fed Spec certified

**Industrial grade dimensional**  
Information: B-14, B-15

**Specification information:**  
Safety grip industrial plugs & connectors: B-22  
Quick grip plugs & connectors: B-22  
Auto grip industrial plugs & connectors: B-22  
Industrial flanged inlets & Flanged outlets: B-23

#### Color information:

BK (Black), W (White), Y (Yellow)





**Compliances, specifications and availability are subject to change without notice.**

## Industrial grade straight blade devices

### Product description


2-pole, 3-wire grounding  
20A, 125V/AC  
NEMA 5-20

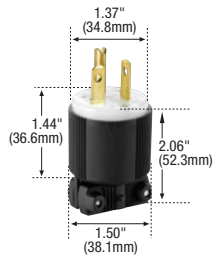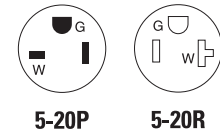

6766



5778C

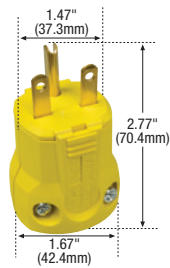

AH5666Y



5679C

### Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	125	5-20	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH5366	<input type="checkbox"/> AH5369	•	•
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	BK	<input type="checkbox"/> AH5364BK	<input type="checkbox"/> AH5369BK		•
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	Y	<input type="checkbox"/> AH5364Y	<input type="checkbox"/> AH5369Y		•

### Industrial grade flanged inlets & outlets




Rating A	V/AC	NEMA	Description	Color	Inlet catalog no.	Outlet catalog no.		
20	125	5-20	Nylon construction, back wire	BK & W	<input type="checkbox"/> 5778C	<input type="checkbox"/> 5779C*	•	•

\* UL Listed only

## Industrial grade straight blade devices

### Product description

2-pole, 3-wire grounding  
15A, 250V/AC  
NEMA 6-15

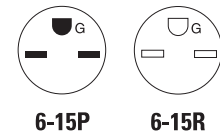

### Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	250	6-15	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> AH5666 <sup>†</sup>	<input type="checkbox"/> AH5669 <sup>†</sup>	•	•
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	Y	<input type="checkbox"/> AH5666Y <sup>†</sup>	<input type="checkbox"/> AH5669Y <sup>†</sup>		•
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	<input type="checkbox"/> 5666N	<input type="checkbox"/> 5669N	•	•

<sup>†</sup> Not NOM Spec

### Industrial grade flanged inlets & outlets



Rating A	V/AC	NEMA	Description	Color	Inlet catalog no.	Outlet catalog no.		
15	250	6-15	Nylon construction, back wire	BK & W	<input type="checkbox"/> 5678C	<input type="checkbox"/> 5679C*	•	•

\* UL Listed only

**Industrial grade dimensional**  
Information: B-14-B15

**Specification Information:**

Safety grip industrial plugs & connectors: B-22  
Quick grip plugs & connectors: B-22  
Auto grip industrial plugs & connectors: B-22  
Industrial flanged inlets & flanged outlets: B-23

**Color information:**

BK (Black), W (White), Y (Yellow)



**Compliances, specifications and availability are subject to change without notice.**

# B

SECTION

## Industrial grade devices

### Industrial grade straight blade devices

#### Product description

2-pole, 3-wire grounding  
20A, 250V/AC  
NEMA 6-20



6-20P




6-20R

#### Industrial grade plugs & connectors



Rating		NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
A	V/AC							
20	250	6-20	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH5466	□ AH5469	• •
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	Y	□ AH5464Y	□ AH5469Y	•
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ 5466N	□ 5469N	• •

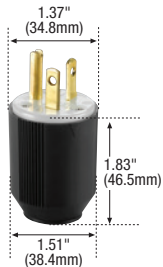

5466N

#### Industrial grade flanged inlets & outlets



Rating		NEMA	Description	Color	Inlet catalog no.	Outlet catalog no.	
A	V/AC						
20	250	6-20	Nylon construction, back wire	BK & W	□ AH5878C	□ AH5879C*	• •

\* UL Listed only



5879C

**Industrial grade dimensional**  
Information: B-14, B-15

**Specification information:**  
Safety grip industrial plugs & connectors: B-22  
Quick grip plugs & connectors: B-22  
Auto grip industrial plugs & connectors: B-22  
Industrial flanged inlets & flanged outlets: B-23

#### Color information:

BK (Black), W (White), Y (Yellow)



**Compliances, specifications and availability are subject to change without notice.**

 
Indicates NAFTA compliant - Page Q-30

RoHS compliant - Page Q-30

## Industrial grade straight blade plugs & connectors

### Product description


2-pole, 3-wire grounding  
20A, 277V/AC  
NEMA 7-20



7-20P


7-20R

### Industrial grade plugs & connectors

Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	
20	277	7-20	Safety grip straight body	0.38"-1.00" (9.6-25.4mm)	BK & W	□ 7624N	•



9151N

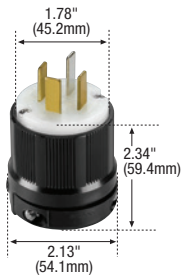


7251N

## Industrial grade straight blade plugs & connectors
 
### Product description


3-pole, 3-wire non-grounding  
20A, 125/250V/AC  
NEMA 10-20



10-20P

10-20R


### Industrial grade plugs & connectors

 Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	
20	125/ 250	10-20	Safety grip straight body	0.38"-1.00" (9.6-25.4mm)	BK & W	□ 9151N	•

## Industrial grade straight blade plugs & connectors

### Product description


4-pole, 4-wire non-grounding  
20A, 3ØY 120/208V/AC  
NEMA 18-20



18-20P

18-20R

### 3ØY industrial grade plugs & connectors

Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	
20	120/ 208	18-20	3ØY safety grip straight body	0.38"-1.00" (9.6-25.4mm)	BK & W	□ 7251N	•

### Color information:

BK (Black), W (White)



**Industrial grade dimensional**  
Information: B-14, B-15

**Specification information:**  
Safety grip industrial plugs &  
connectors: B-22

**Compliances, specifications and availability are subject to change without notice.**

 RoHS compliant – Page Q-30