

### Hospital grade straight blade plugs & connectors

#### Product description


2-pole, 3-wire grounding  
15A, 125V/AC  
NEMA 5-15




5-15P



5-15R

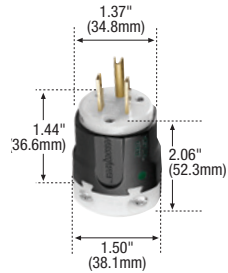

AH8215HG

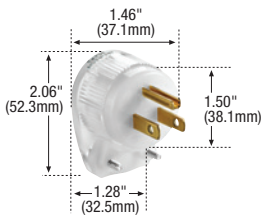

AH8215HGAC



AH8119W



5369NHG

#### Hospital grade plugs & connectors



| Rating<br>A | V/AC | NEMA | Description                                 | Cord<br>diameter           | Color  | Plug<br>catalog no.                 | Connector<br>catalog no.            |   |
|-------------|------|------|---|----------------------------|--------|-------------------------------------|-------------------------------------|---|
| 15          | 125  | 5-15 | Safety grip straight body                   | 0.33-0.66"<br>(8.3-16.7mm) | BK & W | <input type="checkbox"/> AH8215HG   | <input type="checkbox"/> AH8219HG   | • |
|             |      |      | Safety grip straight body                   | 0.33-0.66"<br>(8.3-16.7mm) | C      | <input type="checkbox"/> AH8215HGAC | <input type="checkbox"/> AH8219HGAC | • |
|             |      |      | Safety grip angled body                     | 0.33-0.66"<br>(8.3-16.7mm) | BK & W | <input type="checkbox"/> AH8215HGA  | —                                   | • |
|             |      |      | Safety grip angled body                     | 0.33-0.66"<br>(8.3-16.7mm) | C      | <input type="checkbox"/> AH8215HGAC | —                                   | • |
|             |      |      | Quick grip straight body                    | 0.22-0.66"<br>(5.6-16.7mm) | W      | <input type="checkbox"/> AH8115W    | <input type="checkbox"/> AH8119W    |   |
|             |      |      | Auto grip straight body                     | 0.33-0.66"<br>(8.3-16.7mm) | BK & W | <input type="checkbox"/> 5266NHG    | <input type="checkbox"/> 5269NHG    |   |
|             |      |      | Auto grip isolated ground,<br>straight body | 0.33-0.66"<br>(8.3-16.7mm) | RN     | <input type="checkbox"/> IG5266NHG  | —                                   | • |

### Hospital grade straight blade plugs & connectors

#### Product description

2-pole, 3-wire grounding  
15A, 125V/AC  
NEMA 5-15



5-20P



5-20R

#### Hospital grade plugs & connectors



| Rating<br>A | V/AC | NEMA | Description               | Cord<br>diameter           | Color  | Plug<br>catalog no.                              | Connector<br>catalog no.                       |   |
|-------------|------|------|---------------------------|----------------------------|--------|--|--|---|
| 20          | 125  | 5-20 | Safety grip straight body | 0.33-0.66"<br>(8.3-16.7mm) | BK & W | <input type="checkbox"/> AH8315HG <sup>†</sup>   | <input type="checkbox"/> AH8319HG <sup>†</sup> | • |
|             |      |      | Safety grip angled body   | 0.33-0.66"<br>(8.3-16.7mm) | BK & W | <input type="checkbox"/> AH8315HGA <sup>†</sup>  | —  | • |
|             |      |      | Safety grip angled body   | 0.33-0.66"<br>(8.3-16.7mm) | C      | <input type="checkbox"/> AH8315HGAC <sup>†</sup> | —  | • |
|             |      |      | Auto grip straight body   | 0.33-0.66"<br>(8.3-16.7mm) | BK & W | <input type="checkbox"/> 5366NHG                 | <input type="checkbox"/> 5369NHG               | • |

<sup>†</sup> Not nom spec

**Hospital grade dimensional**  
Information: B-14

#### Specification information:

Safety grip HG plugs & connectors: B-21  
Auto grip HG plugs & connectors: B-21  
Quick grip HG plugs & connectors: B-21  
Ultra grip HG plugs & connectors: B-21

#### Color information:

BK (Black), C (Clear), RN (Orange), W (White)

|         |         |          |         |
|---------|---------|----------|---------|
| BK      | C       | RN       | W       |
| (Black) | (Clear) | (Orange) | (White) |

**Compliances, specifications and availability are subject to change without notice.**



Indicates NAFTA compliant - Page Q-30

# Straight blade plugs & connectors

## Hospital grade straight blade plugs & connectors

### Product description

2-pole, 3-wire grounding  
15A, 250V/AC  
NEMA 6-15

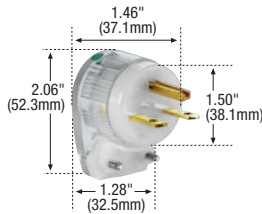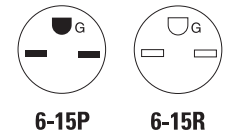

6665HGC

### Hospital grade plugs & connectors




| Rating<br>A | V/AC | NEMA | Description             | Cord<br>diameter           | Color  | Plug<br>catalog no. | Connector<br>catalog no. |   |
|-------------|------|------|-------------------------|----------------------------|--------|---------------------|--------------------------|---|
| 15          | 250  | 6-15 | Safety grip angled body | 0.33-0.66"<br>(8.3-16.7mm) | BK & W | □ 6665HG            | —                        | • |
|             |      |      | Safety grip angled body | 0.33-0.66"<br>(8.3-16.7mm) | C      | □ 6665HGC           | —                        | • |

## Hospital grade straight blade plugs & connectors

### Product description

2-pole, 3-wire grounding  
20A, 250V/AC  
NEMA 6-20

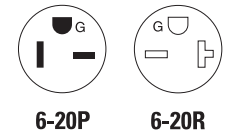

6865HG


### Hospital grade plugs & connectors


 
| Rating<br>A | V/AC | NEMA | Description             | Cord<br>diameter           | Color  | Plug<br>catalog no. | Connector<br>catalog no. |   |
|-------------|------|------|-------------------------|----------------------------|--------|---------------------|--------------------------|---|
| 20          | 250  | 6-20 | Safety grip angled body | 0.33-0.66"<br>(8.3-16.7mm) | BK & W | □ 6865HG            | —                        | • |
|             |      |      | Safety grip angled body | 0.33-0.66"<br>(8.3-16.7mm) | C      | □ 6865HGC           | —                        | • |

### Color information:

BK (Black), C (Clear), W (White)



**Hospital grade dimensional**  
Information: B-14

**Specification information:**  
Safety grip HG plugs &  
connectors: B-21

**Compliances, specifications and availability are subject to change without notice.**

Indicates NAFTA compliant - Page Q-30