

Hospital grade straight blade plugs & connectors

Product description

2-pole, 3-wire grounding
15A, 125V/AC
NEMA 5-15




5-15P



5-15R



6266HG

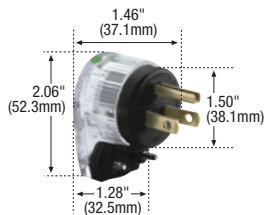

6265HGC



AH8119W



5369NHG

Hospital grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	125	5-15	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH8215HG	□ AH8219HG	•	•
			Safety grip straight body	0.33-0.66" (8.3-16.7mm)	C	□ AH8215HGC	□ AH8219HGC	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH8215HGA	—	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	C	□ AH8215HGAC	—	•	•
			Quick grip straight body	0.22-0.66" (5.6-16.7mm)	W	□ AH8115W	□ AH8119W	•	
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ 5266NHG	□ 5269NHG	•	•
			Auto grip isolated ground, straight body	0.33-0.66" (8.3-16.7mm)	RN	□ IG5266NHG	—	•	•

Hospital grade straight blade plugs & connectors

Product description

2-pole, 3-wire grounding
20A, 125V/AC
NEMA 5-20



5-20P



5-20R

Hospital grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	125	5-20	Ultra grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH8315HG [†]	□ AH8319HG [†]	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH8315HGA [†]	—	•	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	C	□ AH8315HGAC [†]	—	•	•
			Auto grip straight body	0.33-0.66" (8.3-16.7mm)	BK & W	□ 5366NHG [*]	□ 5369NHG	•	•

[†] Not NOM Spec, ^{*} Not Fed Spec

Hospital grade dimensional Information: B-14

Specification information:

Safety grip HG plugs &
connectors: B-21
Auto grip HG plugs &
Connectors: B-21
Quick grip HG plugs &
Connectors: B-21

Color information:

BK (Black), C (Clear), RN (Orange), W (White)

BK	C	RN	W
(Black)	(Clear)	(Orange)	(White)

Compliances, specifications and availability are subject to change without notice.


Indicates NAFTA compliant - Page Q-30

RoHS compliant - Page Q-30

Hospital grade straight blade plugs & connectors

Product description

2-pole, 3-wire grounding
15A, 250V/AC
NEMA 6-15

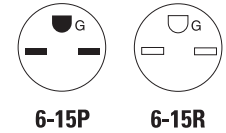

Hospital grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
15	250	6-15	Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH8225HGA	—	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	C	□ AH8225HGAC	—	•



6665HGC




6865HG

Hospital grade straight blade plugs & connectors

Product description

2-pole, 3-wire grounding
20A, 250V/AC
NEMA 6-20

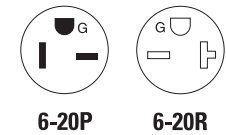


Hospital grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
20	250	6-20	Safety grip angled body	0.33-0.66" (8.3-16.7mm)	BK & W	□ AH8325HGA	—	•
			Safety grip angled body	0.33-0.66" (8.3-16.7mm)	C	□ AH8325HGAC	—	•

Color information:

 BK (Black), C (Clear), W (White)



Hospital grade dimensional
Information: B-14

Specification information:
Safety grip HG plugs &
connectors: B-21

Compliances, specifications and availability are subject to change without notice.

RoHS compliant – Page Q-30