

Hart lock industrial grade 20A locking devices

Product description

3-pole, 4-wire grounding
20A, 125/250V/AC
NEMA L14-20




L14-20R

L14-20P



AHL1420P

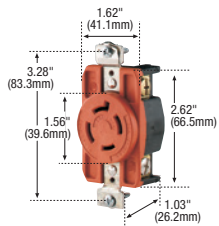

IGL1420R



AH1420FIBK

Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	125/ 250	L14-20	Ultra grip straight body	0.38-1.16" (9.5-29.4mm)	BK & W	☐ AHL1420P	☐ AHL1420C		
			Ultra grip straight body	0.38-1.16" (9.5-29.4mm)	BK	☐ AHL1420PBK	☐ AHL1420CBK		

Industrial grade receptacles



Rating A	V/AC	NEMA	Description	Color	Single receptacle		
20	125/ 250	L14-20	Standard industrial	BK	☐ AHL1420R		
			Isolated ground	RN	☐ IGL1420R*		

*Not Fed Spec

Industrial grade flanged inlets & outlets



Rating A	V/AC	NEMA	Description	Color	Flanged inlet	Flanged outlet		
20	125/ 250	L14-20	Standard industrial	BK & W	☐ AHL1420FI	—		
			Standard industrial	BK	☐ AH1420FIBK	—		
			Standard industrial	BK & W	—	☐ AHL1420FO ^{††}		
			Standard industrial	BK	—	☐ AH1420FOBK ^{††}		

^{††}UL Listed only

Accessories for 20A locking devices

Description	Catalog no.	
Neoprene weather protective boot for 4-W & 5-W plugs	☐ BL1	
Neoprene weather protective boot for 4-W & 5-W connectors	☐ BL2	



BL1



BL2

Dimensional information:
C-76-C-78

Plug & connector specification information:

Ultra grip K14-20: C-84

Receptacle specification information:

K14-20: C-87

Isolated ground K14-20: C-87

Flanged inlet & flanged outlet specification information:

K14-20: C-89

Color information:

BK (Black), RN (Orange), W (White)

BK	RN	W
(Black)	(Orange)	(White)

Compliances, specifications and availability are subject to change without notice.



Indicates NAFTA compliant - Page Q-30



RoHS compliant - Page Q-30