



## Hart lock industrial grade 20A locking devices

### Product description


4-pole, 5-wire grounding  
20A, 3ØY 120/208V/AC  
NEMA L21-20

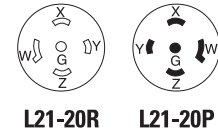

AHL2120PF

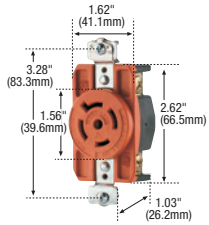

IGL2120R

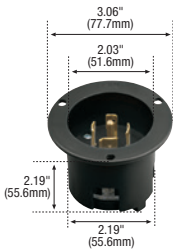

AHL2120FI

### Industrial grade plugs & connectors



Rating	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	US	RoHS
20	120/208	L21-20	3ØY ultra grip straight body	0.38-1.16" (9.5-29.4mm)	BK & W	<input type="checkbox"/> AHL2120P	<input type="checkbox"/> AHL2120C	•	•
			3ØY ultra grip straight body	0.38-1.16" (9.5-29.4mm)	BK	<input type="checkbox"/> AHL2120PBK	<input type="checkbox"/> AHL2120CBK	•	•
			3ØY ultra grip flat cable, straight body	Max. 5-wire #10 AWG flat cable	GY	<input type="checkbox"/> AHL2120PF <sup>†</sup>	<input type="checkbox"/> AHL2120CF <sup>†</sup>	•	•

<sup>†</sup>Only UL Listed

### Industrial grade receptacles



Rating	V/AC	NEMA	Description	Color	Single receptacle	US	RoHS
20	120/208	L21-20	3ØY standard industrial	BK	<input type="checkbox"/> AHL2120R	•	•
			3ØY isolated ground	RN	<input type="checkbox"/> IGL2120R*	•	•

\*Not Fed Spec

### Industrial grade flanged inlets



Rating	V/AC	NEMA	Description	Color	Flanged inlet	US	RoHS
20	120/208	L21-20	3ØY standard industrial	BK	<input type="checkbox"/> AHL2120FI	•	•

### Industrial grade flanged outlets



Rating	V/AC	NEMA	Description	Color	Flanged outlet	US	RoHS
20	120/208	L21-20	3ØY standard industrial	BK & W	<input type="checkbox"/> AHL2120FO	•	•

### Accessories for L21-20 locking devices

Description	Catalog no.	US	RoHS
Neoprene weather protective boot for 4-W & 5-W plugs	<input type="checkbox"/> BL1	•	•
Neoprene weather protective boot for 4-W & 5-W connectors	<input type="checkbox"/> BL2	•	•
Diecast aluminum single receptacle cover, vertical mount, for FS/FD boxes	<input type="checkbox"/> 7420	•	•
Glass-filled nylon flanged inlet/outlet cover, vertical mount, for 20A devices	<input type="checkbox"/> WP2	•	•



BL1



BL2



7420



WP2

**Dimensional information:**  
C-76-C-78

**Plug & connector specification information:**  
Ultra grip K21-20: C-85

**Receptacle specification information:**  
K21-20: C-87

Isolated ground K21-20: C-87

**Flanged inlet & flanged outlet specification information:**  
K21-20: C-89

### Color information:

BK (Black), GY (Gray), RN (Orange), W (White)



**Compliances, specifications and availability are subject to change without notice.**



Indicates NAFTA compliant - Page Q-30



RoHS compliant - Page Q-30