

Hart lock industrial grade 20A locking devices

Product description

2-pole, 3-wire grounding
20A, 125V/AC
NEMA L5-20




L5-20R



L5-20P



AHL520C

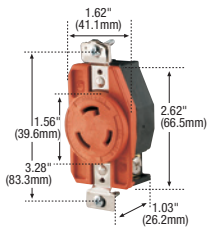

IGL520R



AHL520FO

Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
20	125	L5-20	Ultra grip straight body	0.38-1.16" (9.5-29.4mm)	BK & W	☐ AHL520P	☐ AHL520C	•	•
			Safety grip straight body	0.38-1.00" (9.5-25.4mm)	BK	☐ CWL520PBK	☐ CWL520CBK	•	•

Industrial grade receptacles



Rating A	V/AC	NEMA	Description	Color	Single receptacle		
20	125	L5-20	Standard industrial	BK	☐ AHL520R	•	•
			Isolated ground	RN	☐ IGL520R*	•	•

*Not Fed Spec

Industrial grade flanged inlets & outlets



Rating A	V/AC	NEMA	Description	Color	Flanged inlet	Flanged outlet		
20	125	L5-20	Standard industrial	BK & W	☐ AHL520FI	☐ AHL520FO**	•	•

**Only UL Listed

Accessories for NEMA L5-20 locking devices

Description	Catalog no.		
Neoprene weather protective boot for 20/30A, 3-W locking plug	☐ BM1	•	•
Neoprene weather protective boot for 20/30A, 3-W locking connector	☐ BM2	•	•
Diecast aluminum single receptacle cover, vertical mount, for FS/FD boxes	☐ 7420	•	•



BM1



BM2



7420

Dimensional information:
C-76-C-78Plug & connector specification
information:

Ultra grip K5-20: C-84

Receptacle specification
information:

K5-20: C-87
Isolated ground K5-20: C-87

Flanged inlet & flanged outlet
specification information:

K5-20: C-88

Color information:

BK (Black), RN (Orange), W (White)

BK	RN	W
(Black)	(Orange)	(White)

Compliances, specifications and availability are subject to change without notice.



Indicates NAFTA compliant - Page Q-30



RoHS compliant - Page Q-30