


**Two-way (2/2) general service solenoid valves have one inlet port and one outlet port.**

- Control of air, water, light oil, and non-corrosive media
- Normally closed (opens when energized) and normally open (closes when energized) operation
- Size range of 1/8" to 3"

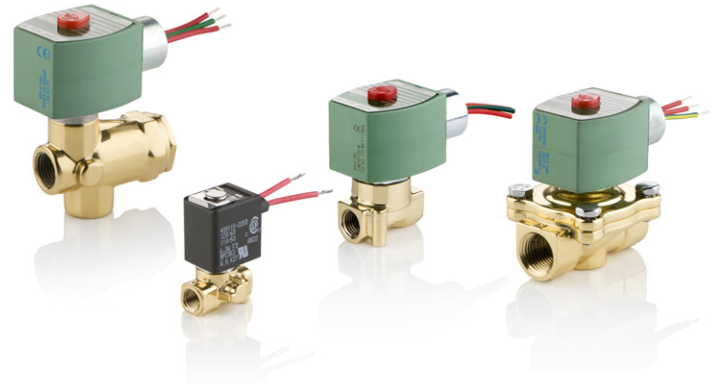

**General Service - 2/2 Normally Closed 1/8"**

Pipe Size (in)	Orifice (in)	Cv Flow	Operating Pressure Differential (psi)			Max. Fluid Temp. °F	Valve Catalog Number	Body Material	Sealing Material	Voltage	Valve Order Code	Wattage	Approvals		Rebuild Kit Order Code	Replacement Coil Order Code	Approx. Shipping Weight (lbs.)	
			Min.	Air	Water								Light Oil	UL				FM
<b>2/2 Normally Closed</b>																		
1/8	3/64	0.06	0	750	750	725	180	8262H001	BR	NBR	120/60,110/50	21959	6.1	○	○	323581	238210-032-D*	2.3
		0.06	0	750	750	725	180	8262H001	BR	NBR	240/60,220/50	22056	6.1	○	○	323581	238210-058-D*	2.3
	1/16	0.08	0	220	220	220	180	SC8256A002V	BR	FKM	24/DC	21833	6.9	□	-	-	400125-142-*	0.5
		0.08	0	220	220	220	180	U8256A002V	BR	FKM	24/DC	21834	6.9	□	-	-	400125-142-D*	0.5
	3/32	0.21	0	370	330	190	180	8262H014	BR	NBR	120/60,110/50	21972	6.1	○	○	323581	238210-032-D*	2.3
			0	370	330	190	180	EF8262H014	BR	NBR	120/60,110/50	21973	6.1	○	○	323581	238214-032-D*	2.3
		0.21	0	235	160	160	180	8262H014	BR	NBR	24/DC	21975	10.6	○	○	323557	238310-006-D*	2.3
			0	235	160	160	180	8262H014	BR	NBR	12/DC	21974	10.6	○	○	323557	238310-004-D*	2.3
	7/64	0.19	0	135	126	80	180	SC8256B045V	BR	FKM	120/60, 110/50	21836	6.3	□	-	-	400125-225-*	0.6
			0	63	63	63	180	U8256B045V	BR	FKM	24/DC	21844	6.9	□	-	-	400125-142-D*	0.6
		0.19	0	135	126	80	180	U8256B045V	BR	FKM	120/60	21843	6.3	□	-	-	400125-225-D*	0.6
			0	135	126	80	180	U8256B046V	SS	FKM	120/60, 110/50	21838	6.3	□	-	-	400125-225-*	0.6
	1/8	0.35	0	185	180	120	180	OPSF8262H002	BR	NBR	120/60,110/50	22064	6.1	○	○	325145	238212-032-*	2.3
			0	185	180	120	180	8262H002	BR	NBR	120/60,110/50	21960	6.1	○	○	3235145	238210-032-D*	2.3
			0	185	180	120	180	8262H002	BR	NBR	24/60	21965	6.1	○	○	3235145	238210-005-D*	2.3
			0	185	180	120	180	8262H002	BR	NBR	240/60,220/50	21963	6.1	○	○	3235145	238210-058-D*	2.3
			0	185	180	120	180	8262H002	BR	NBR	480/60,440/50	21964	6.1	○	○	3235145	238210-088-D*	2.3
			0	185	180	120	180	EF8262H002	BR	NBR	120/60,110/50	21962	6.1	○	○	3235145	238214-032-D*	2.3
			0	185	180	120	180	8262H002V	BR	FKM	120/60,110/50	21961	6.1	○	○	323581-V	238210-032-D*	2.3
			0	130	110	95	180	8262H002	BR	NBR	12/DC	21966	10.6	○	○	323587	238310-006-D*	2.3
0			130	110	95	180	8262H002	BR	NBR	24/DC	21967	10.6	○	○	323587	238310-004-D*	2.3	
0	155	180	140	180	8262H006	SS	NBR	120/60,110/50	21968	6.1	○	○	323583	238210-032-D*	2.3			