


Three-way (3/2) general service solenoid valves have three ports and two orifices. When one orifice is open, the other is closed.

- Control of air, water, light oil, non-corrosive media
- Normally closed (pressure to cylinder port when energized) operation
- Normally open (cylinder port exhausts when energized) operation
- Universal (can function as normally closed, normally open, diverter of 1 fluid, or selector of 2 fluids) operation
- Size range of 1/8" to 1"

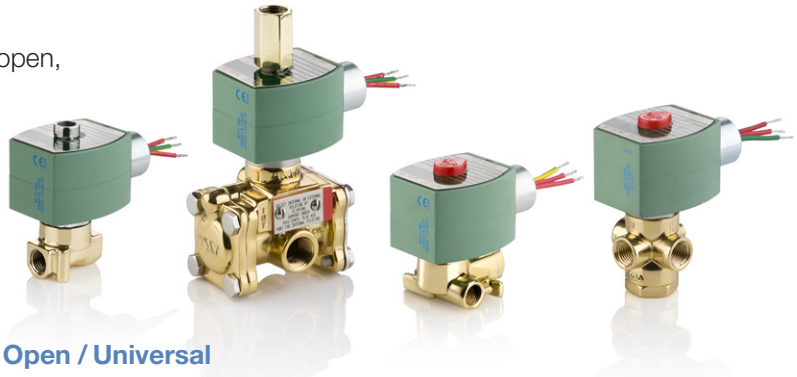

General Service - 3/2 Normally Closed / Normally Open / Universal

Pipe Size (in)	Orifice (in)	Cv Flow	Operating Pressure Differential (psi)				Max. Fluid Temp. °F	Valve Catalog Number	Body Material	Sealing Material	Voltage	Valve Order Code	Wattage	Approvals		Rebuild Kit Order Code	Replacement Coil Order Code	Approx. Shipping Weight (lbs.)
			Min.	Max.										UL	FM			
				Air	Water	Light Oil												
3/2 Normally Closed																		
1/8	3/64	0.06	0	200	200	200	180	8320G132	BR	NBR	120/60,110/50	20710	6.1	●	-	302120	238210-032-D*	2.1
		0.06	0	200	200	200	180	8320G132MS	BR	NBR	120/60,110/50	20900	6.1	●	-	302120-MS	238210-032-D*	2.1
		0.06	0	200	200	200	120	8320G132	BR	NBR	24/DC	21587	10.6	●	-	302216	238310-006-D*	2.1
	1/16	0.09	0	150	125	125	180	8320G013	BR	NBR	120/60,110/50	20674	6.1	●	-	302120	238210-032-D*	2.1
	3/32	0.12	0	100	100	100	180	8320G015	BR	NBR	120/60,110/50	20678	6.1	●	-	302120	238210-032-D*	2.1
3/2 Normally Open																		
1/8	3/64	0.06	0	200	200	200	180	8320G136	BR	NBR	120/60,110/50	20713	6.1	●	-	302156	238210-032-D*	2.1
		0.06	0	200	200	200	180	8320G136MS	BR	NBR	120/60,110/50	20903	6.1	●	-	302156-MS	238210-032-D*	2.1
	3/32	0.12	0	100	100	100	180	8320G029	BR	NBR	120/60,110/50	20687	6.1	●	-	302156	238210-032-D*	2.1
	3/16	0.35	0	250	250	250	200	8300G003G	BR	SS	120/60	21469	20.1	-	-	306680-G	272610-132-D*	3.0
3/2 Universal																		
1/8	3/64	0.06	0	175	175	175	140	8320G130	BR	NBR	120/60,110/50	20706	9.1	●	-	302084	238210-132-D*	2.1
		0.06	0	125	125	125	120	8320G130	BR	NBR	12/DC	20709	10.6	●	-	302190	238310-004-D*	2.1
	1/16	0.08	0	100	100	100	180	8320G001MS	BR	NBR	120/60,110/50	20662	9.1	●	-	302088-MS	238210-132-D*	2.1
		0.08	0	65	65	65	120	8320G001	BR	NBR	24/DC	20669	10.6	●	-	302191	238210-006-D*	2.1
		0.08	0	100	100	100	180	8320G001	BR	NBR	120/60,110/50	20661	9.1	●	-	302088	238210-132-D*	2.1
		0.08	0	100	100	100	180	8320G001	BR	NBR	24/60	21729	9.1	●	-	302088	238210-105-D*	2.1
		0.08	0	100	100	100	180	OPSP8320G001MS	BR	NBR	120/60,110/50	20666	9.1	●	-	302088-MS	238212-132-*	2.1
		0.08	0	100	100	100	180	8320G083	BR	NBR	120/60,110/50	20697	6.1	●	-	302092	238210-032-D*	2.1
	1/8	0.21	0	30	30	30	180	8320G003	BR	NBR	120/60,110/50	20670	9.1	●	-	302096	238210-132-D*	2.1
		0.21	0	30	30	30	180	8320G043	SS	NBR	120/60,110/50	20692	9.1	●	-	302098	238210-132-D*	2.1