


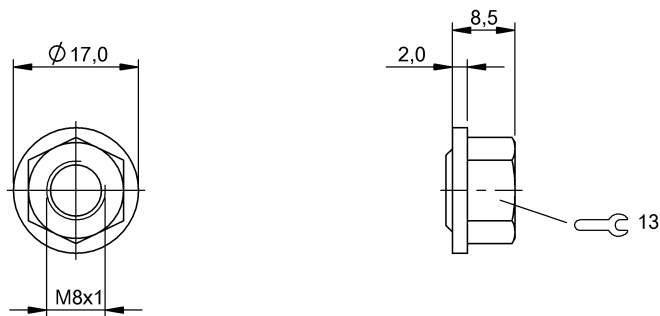

Basic features

Principle of operation	Sealing element
Use	for sealing of pressure rated sensors M8

Environmental conditions

Ambient temperature	-40...110 °C
---------------------	--------------

Material

Gasket, material	PO 11
Material	PA
Surface protection	phosphated

Mechanical data

Pressure max.	400 bar
Tightening torque max.	15 Nm

Remarks

The sealing nut seals simultaneously against liquids and gases after unscrewing and re-tightening up to five times.