


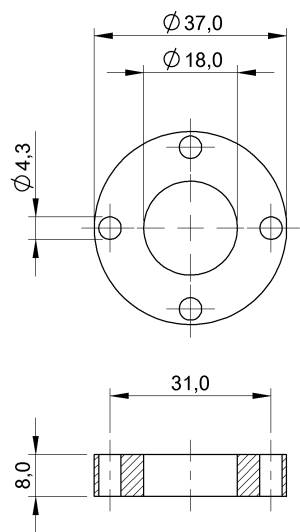

Basic features

Principle of operation	BTL magnet, rod
------------------------	-----------------

Environmental conditions

Ambient temperature	-40...100 °C
Storage temperature	-40...100 °C

Material

Housing material	PA 6.6, GF30
------------------	--------------

Mechanical data

Application weight	16.00 g
Dimension	Ø 37 x 8 mm
Inside diameter	18.0 mm
Mounting part	Through-hole 4.3 mm (4x)
Pressure rating max.	250 bar