


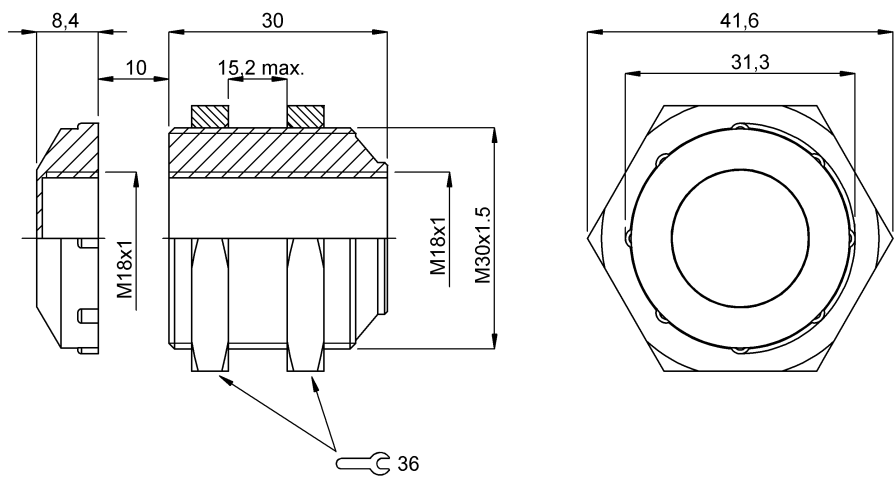

Basic features

Scope of delivery	Protective cap
	Nut M30x1.5 (2x)
Short description	Padded Proxy holder
Use	For M18 sensors
	for inductive sensors BES
	for inductive sensors BES M18

Environmental conditions

Ambient temperature	-45...85 °C
----------------------------	-------------

Material

Housing material	POM, black, Anodized
	Aluminum, black anodized
Material	Aluminum
Surface protection	Anodized

Mechanical data

Clamping system	Threads
Diameter 2	18.00 mm
Dimension	Ø 30 x 29.7 mm
Life expectancy mechanical	2 mil. switching operations
Mounting part	M30x1.5
Size	M18x1
Spring deflection	15 mm
Spring force	5.56 N
Stop force F max.	10.49 N
Tightening torque max.	40 Nm