

Basic features

Approval/Conformity	CE WEEE
---------------------	------------

Electrical connection

Bending radius min., fixed cable	5 x D
Bending radius min., flexible cable	10 x D
Cable	PUR Shielded black, 10 m
Cable diameter D	4.50 mm ±0.20 mm
Conductor cross-section	0.34 mm ²
Connection	M8x1-Female, straight, 3-pin, A-coded
Connector configuration	Straight
Number of conductors	2
Number of pins	3
System	Molded

Electrical data

Operating voltage U _b	36 VDC / 30 VAC
Rated current (40 °C)	3.0 A

Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

Environmental conditions

Ambient temperature	-25...90 °C
Cable temperature, fixed routing	-40...70 °C
Cable temperature, flexible routing	5...70 °C
IP rating	IP67


Material

Cable jacket material, note	Shielded
Cable jacket, material	PUR
Material contact carrier	PUR
Material contacts	Bronze
Material cover nut	Brass
Material grip	PUR

Mechanical data

Cable jacket, color	black
Cable length L	10.00 m
Tightening torque pigtail	0.4 Nm

Connector Drawings

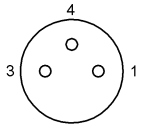

PIN 1: brown

PIN 3: blue

PIN 4: Shield