

### Basic features

Approval/Conformity	CE WEEE
---------------------	------------

### Display/Operation

Function indicator	LED yellow
--------------------	------------

### Electrical connection

Bending radius min., fixed cable	5 x D
Bending radius min., flexible cable	10 x D
Cable	PVC gray, 2 m
Cable diameter D	5.00 mm ±0.20 mm
Conductor cross-section	0.50 mm <sup>2</sup>
Connection	B, Ind.-0°-Valve connector, angled, 3-pin
Connector configuration	right-angle
Number of conductors	3
Number of pins	3
System	Molded

### Electrical data

Operating voltage $U_b$	24 VDC / 24 VAC
Rated current (40 °C)	4.0 A
Suppressor	Suppressor diode

### Environmental conditions

Cable temperature, fixed routing	-40...105 °C
Cable temperature, flexible routing	-5...105 °C
IP rating	IP67

### Material

Cable jacket, material	PVC
Material contact carrier	PBT
Material contacts	Brass
Material grip	PUR
Material locking screw	Steel


### Mechanical data

Cable jacket, color	gray
Cable length L	2.00 m
Tightening torque pigtail	0.5 Nm

## Remarks

Flame resistance per IEC 60332-1-2  
\* style B industry standard  
Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

## Connector Drawings

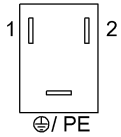

PIN 1: brown  
PIN 2: blue  
PIN PE: green/yellow

## Wiring Diagrams

