

### Basic features

Approval/Conformity	CE cURus WEEE
---------------------	---------------------

### Electrical connection

Cable diameter D	8...10 mm
Connection	7/8"-16 UN-Male, straight, 5-pin
Number of connectable contacts	5
System	Can be fabricated

### Electrical data

Operating voltage $U_b$	600 VDC / 600 VAC
Rated current (40 °C)	10.0 A

### Environmental conditions

Ambient temperature	-25...85 °C
IP rating	IP67

### Material

Material contact carrier	PUR, PA
Material contacts	Brass
Material cover nut	Die-cast zinc
Material grip	PBT


### Mechanical data

Connection cross-section	0.14...1.5 mm <sup>2</sup>
Tightening torque pigtail	1.5 Nm
Type of wire mounting	Screw terminals

### Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

## Connector Drawings

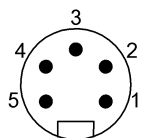

PIN 1-5 usable