

### Basic features

Approval/Conformity WEEE

### Display/Operation

Power indicator no/no

### Electrical connection

Connection 1 M12x1-Female, straight, 4-pin, D-coded  
 Connection 2 RJ45-Female, straight, 4-pin  
 Connector 01, version straight  
 Connector 02, version straight  
 Number of pins 4/4

### Electrical data

Operating voltage  $U_b$  60 VDC / 60 VAC  
 Rated current (40 °C) 0.5 A

### Environmental conditions

Ambient temperature -20...80 °C  
 IP rating IP67/IP20

### Material

Material contact carrier PUR  
 Material contacts Brass/Brass  
 Material grip PUR


### Mechanical data

Mounting part M16x1.5


### Remarks

Enclosure rating per IEC 60529 or 20653, only in mounted and screwed state with the associated mating piece.

## Connector Drawings

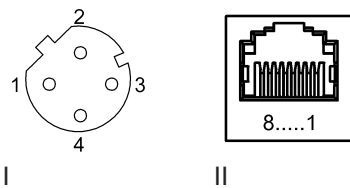

## Wiring Diagrams

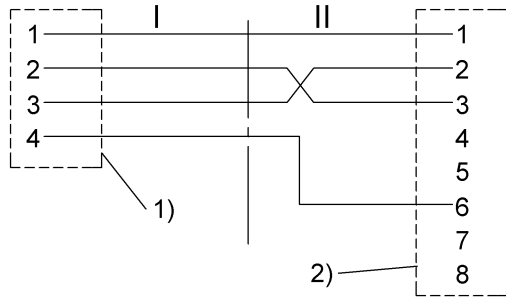

- 1) Shield on cover nut
- 2) Shield on housing