

**Basic features**

Approval/Conformity	CE cURus WEEE
---------------------	---------------------

**Environmental conditions**

Ambient temperature	-25...80 °C
IP rating	IP67

**Electrical connection**

Connection 1	M12x1-Male, 5-pin, A-coded
Connection 2	M12x1-Female, 4-pin, A-coded
Connection 3	M12x1-Female, 4-pin, A-coded
Number of pins	5/4/4

**Material**

Material contacts	Copper alloy, gold plated/Copper alloy, gold plated/Copper alloy, gold plated
Material cover nut	Brass nickel-plated
Material grip	PA 6.6 GF

**Electrical data**

Operating voltage Ub	125 VDC / 125 VAC
Rated current (40 °C)	4.0 A


**Mechanical data**

Tightening torque pigtail	0.6 Nm/-/-
---------------------------	------------

**Remarks**

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

**Connector Drawings**

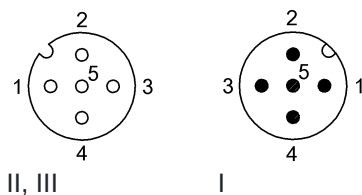

## Wiring Diagrams

