

#### Basic features

Approval/Conformity	CE WEEE
---------------------	------------

#### Electrical connection

Cable diameter D	6...10 mm
Connection	M23x1-Female, angled, 12-pin
Number of connectable contacts	12
System	Can be fabricated

#### Electrical data

Operating voltage $U_b$	150 VDC
Rated current (40 °C)	8.0 A

#### Environmental conditions

Ambient temperature	-20...125 °C
IP rating	IP67

#### Material

Material grip	Brass nickel-plated
---------------	------------------------


#### Mechanical data

Connection cross-section	1.00 mm <sup>2</sup>
Type of wire mounting	Solder connections

#### Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

## Connector Drawings

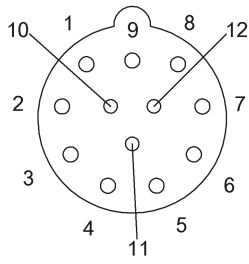

I