

### Basic features

Approval/Conformity	CE Ecolab WEEE
---------------------	----------------------

### Electrical connection

Cable diameter D	4...6 mm
Connection	M12x1-Female, straight, 5-pin, A-coded
Number of connectable contacts	5
System	Can be fabricated

### Electrical data

Operating voltage $U_b$	125 VDC / 125 VAC
Rated current (40 °C)	4.0 A

### Environmental conditions

Ambient temperature	-40...85 °C
IP rating	IP67

### Material

Material contact carrier	PA
Material contacts	Brass
Material cover nut	1.4404 stainless steel
Material grip	PA


### Mechanical data

Connection cross-section	0.14...0.75 mm <sup>2</sup>
Tightening torque pigtail	0.6 Nm
Type of wire mounting	Screw terminals

### Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

## Connector Drawings

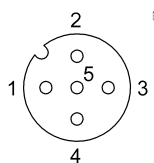

PIN 1-4 usable