

## Basic features

Application	Operating voltage
Approval/Conformity	CE cULus WEEE

## Electrical connection

Cable	TPE Yellow, 10 m
Cable diameter D	10.88 mm ±0.25 mm
Conductor cross-section	16 AWG
Connection	7/8"-Female, angled, 4-pin
Connector configuration	right-angle
Number of conductors	4
Number of pins	4
System	Molded

## Electrical data

Cable rated voltage AC max.	600 V
Cable rated voltage DC max.	600 V
Operating voltage $U_b$	300 VDC / 300 VAC
Operating voltage $U_b$ 3-phase network	277/480V AC +/- 15%
Rated current (40 °C)	10.0 A

## Environmental conditions

IP rating	IP67, IP68
-----------	------------

## Material

Cable jacket, material	TPE
Material contact carrier	PUR
Material contacts	Brass
Material cover nut	Die-cast zinc
Material grip	PUR


## Mechanical data

Cable jacket, color	Yellow
Cable length L	10.00 m
Tightening torque pigtail	1.5 Nm

## Remarks

Cable construction acc. to UL-AWM Style 2037  
 Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

## Connector Drawings

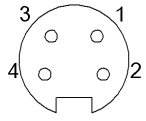

PIN 1: brown

PIN 2: white

PIN 3: blue

PIN 4: black

## Wiring Diagrams

