

Basic features

Approval/Conformity	CE
	cURus
	WEEE

Electrical data

Operating voltage U_b	300 VDC / 300 VAC
Rated current (40 °C)	9.0 A

Electrical connection

Connection 1	7/8"-16 UN-Female, 4-pin
Connection 2	7/8"-16 UN-Female, 4-pin
Connection 3	7/8"-16 UN-Male, 4-pin
Number of pins	4/4/4

Environmental conditions

Ambient temperature	-25...80 °C
IP rating	IP67


Material

Material cover nut	Die-cast zinc nickel-plated
Material grip	PA 6.6 GF

Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

Connector Drawings

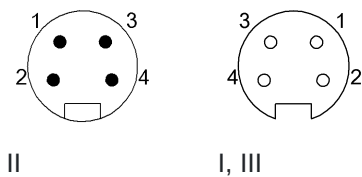

Wiring Diagrams

