

1) Identification clip, white



## Basic features

Approval/Conformity	CE WEEE
---------------------	------------

## Electrical connection

Bending radius min., fixed cable	5 x D
Bending radius min., flexible cable	15 x D
Cable	PUR black, 10 m
Cable diameter D	5.30 mm ±0.20 mm
Conductor cross-section	0.34 mm <sup>2</sup>
Connection	M12x1-Female, angled, 5-pin, A-coded
Connector configuration	right-angle
Number of conductors	4
Number of pins	5
System	Molded

## Electrical data

Operating voltage Ub	250 VDC / 250 VAC
Rated current (40 °C)	4.0 A

## Remarks

Halogen-free  
 Silicone-free  
 Flame resistance acc. to IEC 60332-1  
 Enclosure rating per IEC 60529 or 20653, only in screwed state with the associated mating piece.

## Environmental conditions

Ambient temperature	-25...120 °C
Cable temperature, fixed routing	-40...120 °C
IP rating	IP67, IP68, IP69K

## Interface

Switching output	Complementary
------------------	---------------


## Material

Cable jacket, material	PUR
Material contact carrier	PUR
Material contacts	Bronze
Material cover nut	Die-cast zinc
Material grip	PUR

## Mechanical data

Cable jacket, color	black
Cable length L	10.00 m
Tightening torque pigtail	0.6 Nm

## Connector Drawings

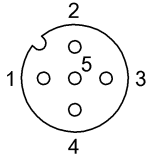

PIN 1: brown

PIN 2: white

PIN 3: blue

PIN 4: black

## Wiring Diagrams

