

1) from cable drum

Basic features

Application	Operating voltage
--------------------	-------------------

Electrical connection

Cable	PVC Yellow, 100 m
Cable diameter D	10.67 mm ±0.25 mm
Conductor cross-section	16 AWG
Number of conductors	4

Electrical data

Operating voltage U_b	600 VDC / 600 VAC
--	-------------------

Environmental conditions

Cable temperature, fixed routing	-40...105 °C
---	--------------

Material

Cable jacket, material	PVC
-------------------------------	-----


Mechanical data

Cable jacket, color	Yellow
Cable length L	100.00 m

Remarks

Bulk cable: PVC UL listed, 16/4 STOOW/MaleOOW CSA 105°C 600 V

Connector Drawings

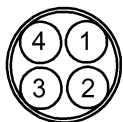

Conductor diagram

Conductor 1: brown

Conductor 2: white

Conductor 3: blue

Conductor 4: black

Wiring Diagrams

