

## Basic features

Application	Operating voltage
Approval/Conformity	CE cULus WEEE

## Electrical connection

Cable	PVC Yellow, 30 m
Cable diameter D	12.58 mm ±0.25 mm
Conductor cross-section	16 AWG
Connection	7/8"-Female, straight, 5-pin
Connector configuration	Straight
Number of conductors	5
Number of pins	5
System	Molded

## Electrical data

Cable rated voltage AC max.	600 V
Cable rated voltage DC max.	600 V
Operating voltage U <sub>b</sub>	300 VDC / 300 VAC
Operating voltage U <sub>b</sub> 3-phase network	277/480V AC +/- 15%
Rated current (40 °C)	9.0 A

## Remarks

Bulk cable: PVC UL listed, 16/5 STOOW/STOOW CSA 105°C 600 V  
 Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

## Environmental conditions

Cable temperature, fixed routing	-40...105 °C
IP rating	IP67, IP68


## Material

Cable jacket, material	PVC
Material contact carrier	PUR
Material contacts	Brass
Material cover nut	Die-cast zinc
Material grip	PUR

## Mechanical data

Cable jacket, color	Yellow
Cable length L	30.00 m
Tightening torque pigtail	1.5 Nm

## Connector Drawings

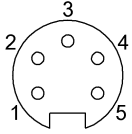

PIN 1: black

PIN 2: blue

PIN 3: green/yellow

PIN 4: brown

PIN 5: white

## Wiring Diagrams

