

1) from cable drum

Electrical connection

Bending radius min., fixed cable	5 x D
Bending radius min., flexible cable	15 x D
Cable	PUR black, 100 m
Cable diameter D	5.30 mm ±0.20 mm
Conductor cross-section	0.34 mm ²
Number of conductors	4

Environmental conditions

Cable temperature, fixed routing	-40...120 °C
----------------------------------	--------------

Material

Cable jacket, material	PUR
------------------------	-----


Mechanical data

Cable jacket, color	black
Cable length L	100.00 m

Remarks

Halogen-free per DIN VDE 0472 Part 815
Flame resistance acc. to IEC 60332-1

Connector Drawings

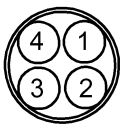

Conductor diagram
Conductor 1: brown
Conductor 2: white
Conductor 3: blue
Conductor 4: black